



120X120X38 mm

93~138 CFM



	Bearing	Rating Voltage (VDC)	Power Current (AMP)	Power Consumption (WATTS)	Speed (RPM)	Air Flow (CFM)	Static Pressure (Inch-H ₂ O)	Noise (dBA)	Weight (g)	Curve
	● VAPO									
MEC0381V1-0000-A99	●	12	0.833	10.0	3100	138	0.36	48	218	1
MEC0381V2-0000-A99	●	12	0.421	5.1	2600	116	0.26	44	218	2
MEC0381V3-0000-A99	●	12	0.241	2.9	2100	93	0.18	37	218	3
MEC0382V1-0000-A99	●	24	0.383	9.2	3100	138	0.36	48	218	1
MEC0382V2-0000-A99	●	24	0.224	5.4	2600	116	0.26	44	218	2
MEC0382V3-0000-A99	●	24	0.130	3.1	2100	93	0.18	37	218	3
MEC0384V1-0000-A99	●	48	0.203	9.7	3100	138	0.36	48	218	1
MEC0384V2-0000-A99	●	48	0.120	5.8	2600	116	0.26	44	218	2
MEC0384V3-0000-A99	●	48	0.068	3.3	2100	93	0.18	37	218	3

Model	 2BALL  Sleeve	(VDC)	(AMP)	(WATTS)	(RPM)	(CFM)	(Inch-H ₂ O)	(dBA)	(g)	Curve
EEC0381B1-0000-A99		12	0.833	10.0	3100	138	0.36	48	214	1
EEC0381B2-0000-A99		12	0.421	5.1	2600	116	0.26	44	214	2
EEC0381B3-0000-A99		12	0.241	2.9	2100	93	0.18	37	214	3
EEC0382B1-0000-A99		24	0.383	9.2	3100	138	0.36	48	214	1
EEC0382B2-0000-A99		24	0.224	5.4	2600	116	0.26	44	214	2
EEC0382B3-0000-A99		24	0.130	3.1	2100	93	0.18	37	214	3
EEC0384B1-0000-A99		48	0.203	9.7	3100	138	0.36	48	214	1
EEC0384B2-0000-A99		48	0.120	5.8	2600	116	0.26	44	214	2
EEC0384B3-0000-A99		48	0.069	3.3	2100	93	0.18	37	214	3

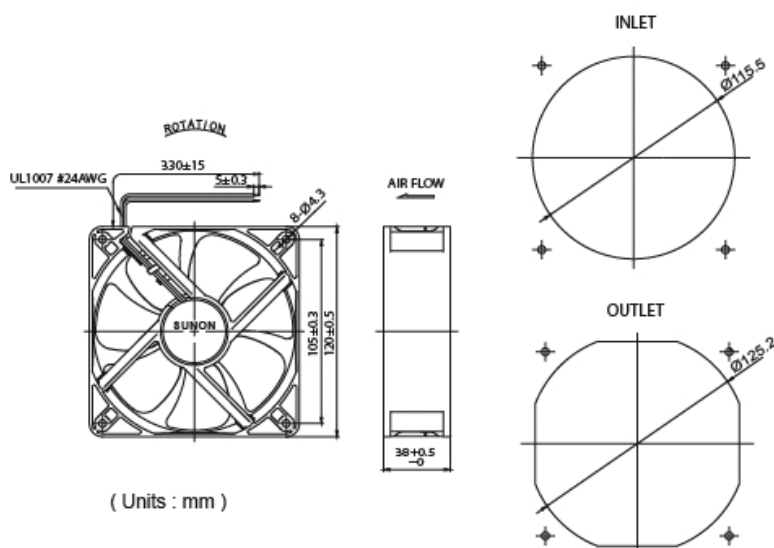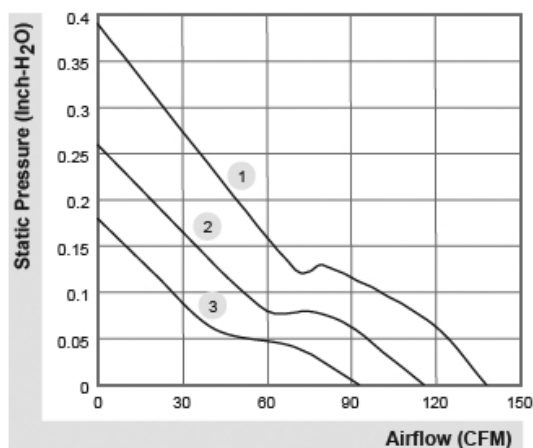

*All model could be customized. Please contact with Sunon Sales.

*Specifications are subject to change without notice. Please Visit SUNON web site at <http://www.sunon.com> for update information.