

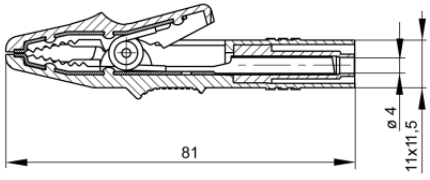


Crocodile clips

AK 2 B



Product	AK 2 B
description	Contact-protected, high strength alligator clip. Clamping range up to a bolt diameter of 9.5 mm. The part of the jaws (fine wire section) allows a secure contact to be made when clamping even the thinner wire. 4 mm diameter brass socket connection.
operating instruction	BA465
article-no. / *colour	9324351xx <div style="display: flex; justify-content: space-around; align-items: center;"> <div style="text-align: center;">  00 black </div> <div style="text-align: center;">  01 red </div> </div> <div style="text-align: right; border: 1px solid black; padding: 2px; margin-top: 10px;">Ni</div>
drawing	
technical data	
connection	unsprung socket 4 mm
rated voltage	AC/DC 300 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	25 A
material socket	brass, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +80 °C
inflammability class acc. to UL 94 (only valid for basic material of housing)	HB
clamping range	9,5 mm

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 21.06.2022

stand: 21.06.2022