


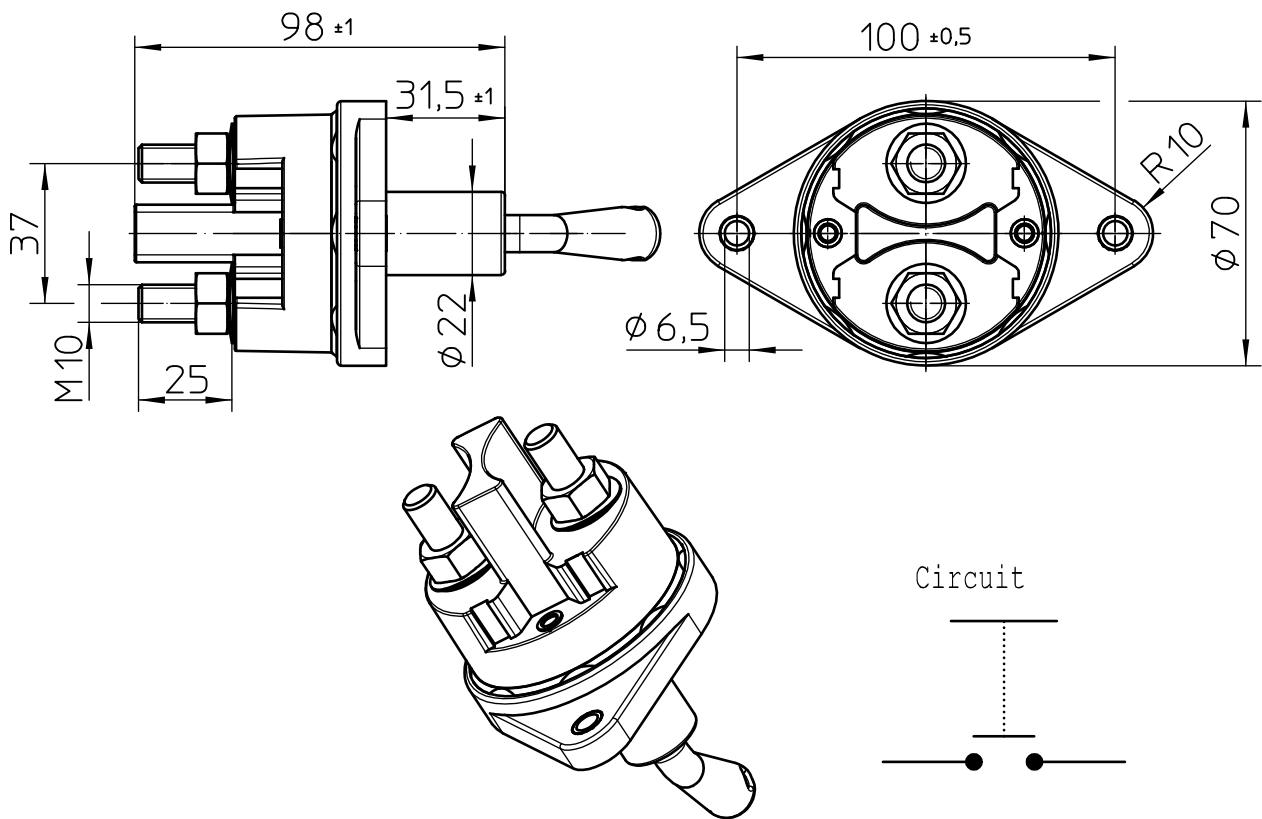

Technical Data:

Case Material: Cover	Vyncolit black
Base Plate	PA GF black
Switch Lever Material	PA GF black
Min. Insulation Resistance	100MOhm
Dielectric Withstanding Voltage	1050V-1min.
Max. Contact Drop during Resistive Load	150mV
Voltage	to 32VDC
Duty Rating	500A
Overload	1500A-4min.
.....	2000A-1.5min.
.....	2500A-10sec
Sealing	IP 67/ IEC 529
Vibration	4G/ 50-2000Hz
Shock G-Level	6G/ 11ms
Weight	340g/ 0.75 Pound
Temperature Range	-40°C to +85°C
Wire Section (At Nominal Load)	min. 250mm ²
Switch lever	removeable
Max. Tourque (Main Contacts)	15-20Nm