


PS02/A0120/63 Datasheet

Product Name // Mains Filter Base Mount 6.3mm Tab Termination A0120 Filter (1A PS02/A L/C v2)

[View Product Page](#)

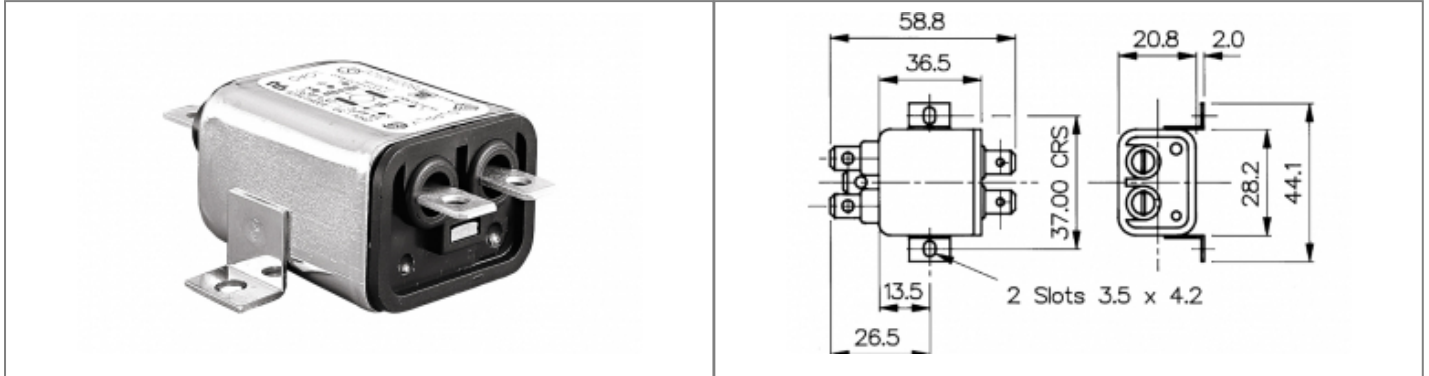

// Product Description:

- ⊕ Standalone Mains Filter
- ⊕ 6.3mm Tab Termination
- ⊕ Choice of mounting type depending on part code:
- ⊕ Part codes prefixed PS02/A: Base Mount
- ⊕ Part codes prefixed PS03/A: Bulkhead Mount
- ⊕ Choice of 1A, 3A, 6A, 10A current ratings and three alternative filter L/C circuits depending on part code starting /A - see data for details

// General Information:

Product Display Title:	Standalone Mains Filter
Product Family:	IEC Connectors
Product Series:	Mains Filters
Approvals:	CSA, ENEC, UL, VDE
Current Max:	1A
Filter Type:	1A PS02/A L/C v2
Flamability Rating:	UL94V-0
Function:	Mains Filter
iec Filter Options:	A0120
Inlet Type:	IEC Inlet
Max Operating Temperature:	+85°C
Min Operating Temperature:	-25°C
Voltage Max:	250V

// Product PDF Links

 [Mains Filters product data](#)