


SS35V-35047

Aliases (UAL35V35047000, SS35V/H-35047)

Not for New Design

KEMET, SS35V/35H, AC Line Filters, Common Mode, 4.7 mH

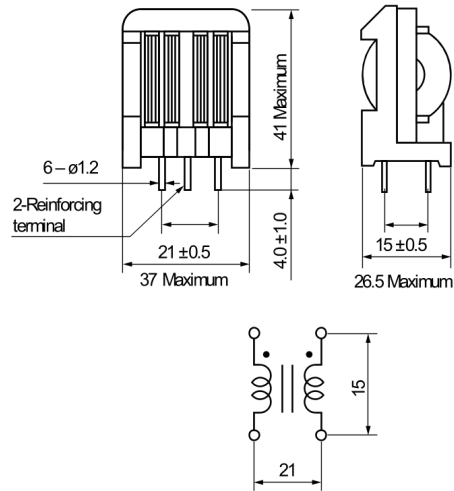

General Information

Series	SS35V/35H
Style	Through-Hole
RoHS	Yes
Miscellaneous	Inductance Measurement Condition: 1kHz 1V KC530.

Specifications

Voltage AC	250 VAC
Inductance	4.7 mH
Current	3.5 A
Temperature Range	-25/+120°C
DC Resistance	0.1 Ohms

Dimensions

L	37mm MAX
T	26.5mm MAX
H	41mm MAX
LL	4mm +/-1mm
S	21mm +/-0.5mm
S1	15mm +/-0.5mm

Packaging Specifications

Typical Component Weight	57 g
--------------------------	------