



Cable clip with pipe/tube holder/for screw fixation, Ø4.0 mm, Dmin=20.0mm, Dmax=20.0mm, black, 100pcs.

Art.-No. 211-70002 | 4D20-POM-BK | [Details](#)

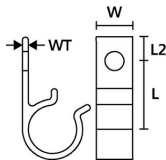

- Guaranteed time and cost saving by simply pressing cable into holder
- Flexible grip for later removal or replacement of cables
- 3 different bore diameters available for fixing holders

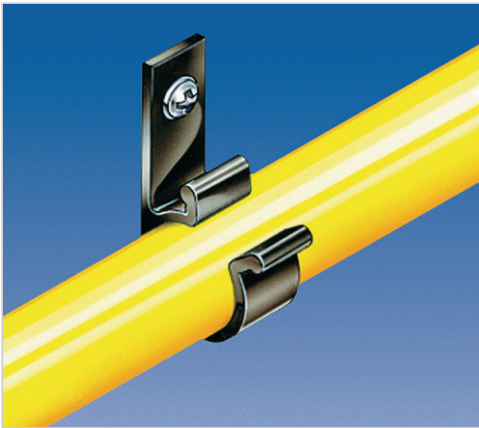

More products in this product group:

[Screw Mount >](#)



Base Data

Application	Developed for fixing pipes, cables and hoses, the D-Clips elastic locking system ensures optimal fixing and at the same time, easy removal of the fixed elements by simply pressing the lower latch down and pulling the fixed element.
Colour	Black (BK)
Fixation Method	screw-hole
Material	Polyacetal (POM)
Pack Content	100 pcs.
Package Content packed in	bag
PART DESCRIPTION	4D20-POM-BK
Product Family	D-Clip Series
Product Group	Screw Mount
Variant	Closed

Bundle Diameter max (metric)	20.0 mm
Bundle \emptyset min.	20.0 mm
for Hole \emptyset (FH)	4.0 mm
Length (L)	28.0 mm
Length (L2)	10.0 mm
Nominal \emptyset	20.0 mm
Nominal \emptyset	0.75 "
Wall (WT)	2.5 mm
Wall (WT)	0.10 "
Width (W)	15.0 mm

Specifications

ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 HB
Hazardous Goods	No
Operating Temperature	-40 °C to +90 °C, (+160 °C, for 200 h)
Specifications	RoHS ✓
UV-Stabilised (Yes/No)	No

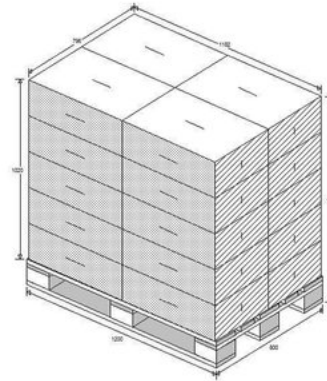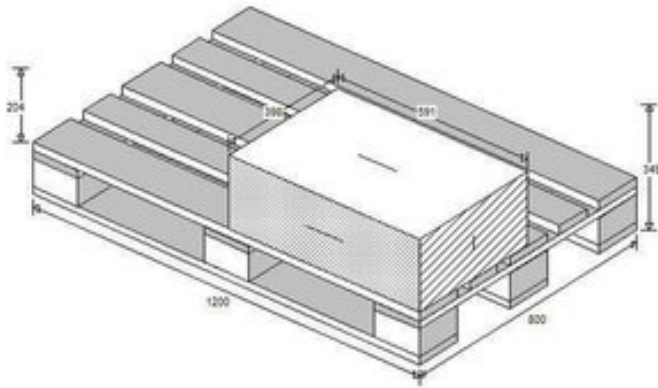

GTIN-13 / EAN	5022660301223
Packaging 1 - Height (m)	0.05 m
Packaging 1 - Length (m)	0.356 m
Packaging 1 - Qty	100
Packaging 1 - Type	bag
Packaging 1 - Volume (m ³)	0.00543 m ³
Packaging 1 - Weight (kg)	0.600001 kg
Packaging 1 - Width (m)	0.305 m
Packaging 3 - Height (m)	0.192 m
Packaging 3 - Length (m)	0.586 m
Packaging 3 - Qty	2000
Packaging 3 - Type	box
Packaging 3 - Volume (m ³)	0.0439 m ³
Packaging 3 - Weight (kg)	12.802 kg
Packaging 3 - Width (m)	0.39 m
Packaging 4 - Height (m)	1.164 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	40000
Packaging 4 - Type	pallet
Packaging 4 - Volume (m ³)	1.117 m ³
Packaging 4 - Weight (kg)	277.04 kg
Packaging 4 - Width (m)	0.8 m

UNSPSC Key

39121702

© HellermannTyton 2024 (v4.239) | Update: 24/03/2024 | [Privacy Settings](#)