


**Cable clip for hole (round)/for stud, ØM6,
Dmin=10.0mm, Dmax=12.0mm, ØM6, black, 20pcs.
Art.-No. 151-03425 | DHVC10-12-PA6GF30/TPV-BK |**

Details

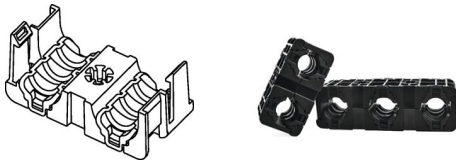

- Product consists of two halves (pieces) that create one complete bracket
- Each product includes TPV soft inserts designed to provide a cushion of protection around the cable
- Rubberised insert provides grip on cable and flexes to suit various cable diameters
- All products have a standardised fixing method with an M6 or M8 bolt
- Fully releasable to aid maintenance
- Multiple clamps can be stacked on a single bolt/stud
- New, modified design available since Q2/2024 to meet customer requirements even better
- New pre-lock feature allowing temporary holding of cables whilst leaving room to adjust the routing


More products in this product group:
[Fixing elements for tubes and harnesses >](#)



Base Data

Application	The HVCC bracket range is designed to hold multiple cables in line, they can be used to secure cables to the body panel or chassis using an M6 bolt or stud. They can also be used as a spacer along the length of the cables. The clamps have a high "pull apart" resistance and can be used in environments up to 90°C.
Colour	Black (BK)
Key product features	vibration absorbing, sealed, for multiple routing
Material	Polyamide 6, glass-fibre reinforced (PA6GF30), Thermoplastic Elastomer (TPV)
Pack Cont.	20 pcs.
Package Content packed in	Pack
PART DESCRIPTION	DHVC10-12-PA6GF30/TPV-BK
Product Family	for multiparallel routing
Product Group	Fixing elements for tubes and harnesses

Attach to Ø	10, 12
Bundle Diameter max (Metric)	12.0 mm
Bundle Ø	10.0-12.0 mm
Bundle Ø min.	10.0 mm
for Hole Ø (FH)	M6
Length (L)	59.0 mm
Stud Ø	M6
Weight/Unit	0.018187 kg
Width (W)	30.0 mm

Specifications

ELV compliant Dir. Art. 4 (2)	YES
Hazardous Goods	No
Operating Temperature	-40 °C to +90 °C
Specifications	

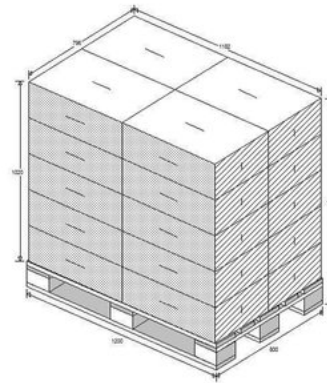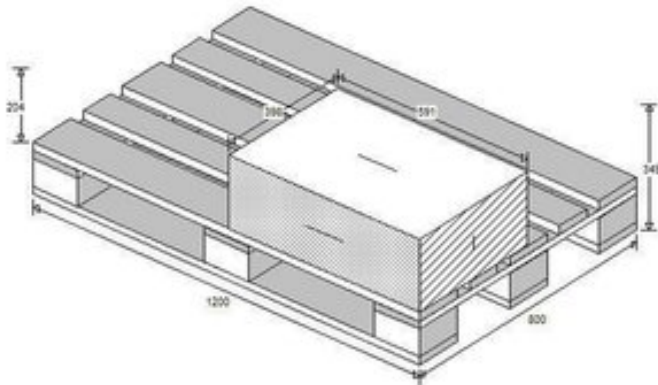

Country of Origin	GB
Customs Number	39269097
GTIN-13 / EAN	4031026661292
Packaging 1 - Height (m)	0.05 m
Packaging 1 - Length (m)	0.37 m
Packaging 1 - Qty	20
Packaging 1 - Type	Bag
Packaging 1 - Volume (m ³)	0.00555 m ³
Packaging 1 - Weight (kg)	0.37674 kg
Packaging 1 - Width (m)	0.3 m
Packaging 3 - Height (m)	0.192 m
Packaging 3 - Length (m)	0.586 m
Packaging 3 - Qty	400
Packaging 3 - Type	Box
Packaging 3 - Volume (m ³)	0.0439 m ³
Packaging 3 - Weight (kg)	8.3368 kg
Packaging 3 - Width (m)	0.39 m
Packaging 4 - Height (m)	1.164 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	8000
Packaging 4 - Type	pallet
Packaging 4 - Volume (m ³)	1.117 m ³

More Information

ETIM 7.0 Key	EC000127
ETIM 8.0 Key	EC000127
ETIM 9.0 Key	EC000127
UNSPSC Key	39121702