



Visit the website for your country to get more information and discover our products.

India

Proceed




# HellermannTyton

25/03/2024

**Cable clip for hole (round)/for stud, ØM6,  
Dmin=18.0mm, Dmax=20.0mm, ØM6, black, 400pcs.  
Art.-No. 151-03345 | DHVC18-20-PA6GF30/TPV-BK |**

## Details

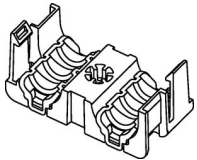

- Product consists of two halves (pieces) that create one complete bracket
- Each product includes TPV soft inserts designed to provide a cushion of protection around the cable
- Rubberised insert provides grip on cable and flexes to suit various cable diameters
- All products have a standardised fixing method with an M6 or M8 bolt



Visit the website for your country to get more information and discover our products.

Proceed

# HellermannTyton

25/03/2024

New pre-look feature allowing temporary holding of cables whilst leaving room to adjust the routing



More products in this product group:  
[Fixing elements for tubes and harnesses >](#)

## Base Data

Application	The HVCC bracket range is designed to hold multiple cables in line, they can be used to secure cables to the body panel or chassis using an M6 bolt or stud. They can also be used as a spacer along the length of the cables. The clamps have a high "pull apart" resistance and can be used in environments up to 90°C.
Colour	Black (BK)
Key product features	vibration absorbing, sealed, for multiple routing
Material	Polyamide 6, glass-fibre reinforced (PA6GF30), Thermoplastic Elastomer (TPV)
Pack Cont.	400 pcs.
Package Content packed in	bag
PART DESCRIPTION	DHVC18-20-PA6GF30/TPV-BK
Product Family	for multiparallel routing
Product Group	Fixing elements for tubes and harnesses



Visit the website for your country to get more information and discover our products.

Proceed

# HellermannTyton

25/03/2024

Bundle $\emptyset$ min.	18.0 mm
for Hole $\emptyset$ (FH)	M6
Length (L)	72.0 mm
Stud $\emptyset$	M6
Weight/Unit	0.024 kg
Width (W)	36.0 mm

## Specifications

ELV compliant (Article 4 - 2)	YES
Hazardous Goods	No
Specifications	<b>RoHS</b> ✓





Visit the website for your country to get more information and discover our products.

Proceed

# HellermannTyton

25/03/2024

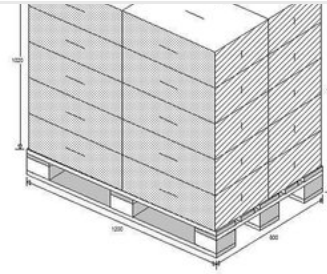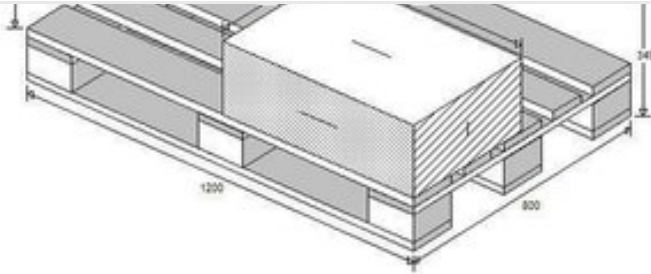

Country of Origin	GB
Customs Number	39269097
GTIN-13 / EAN	4031026652900
Packaging 1 - Height (m)	0.08 m
Packaging 1 - Length (m)	0.28 m
Packaging 1 - Qty	20
Packaging 1 - Type	bag
Packaging 1 - Volume (m <sup>3</sup> )	0.00381 m <sup>3</sup>
Packaging 1 - Weight (kg)	0.480001 kg
Packaging 1 - Width (m)	0.17 m
Packaging 3 - Height (m)	0.192 m
Packaging 3 - Length (m)	0.586 m
Packaging 3 - Qty	400
Packaging 3 - Type	box
Packaging 3 - Volume (m <sup>3</sup> )	0.0439 m <sup>3</sup>
Packaging 3 - Weight (kg)	10.40202 kg
Packaging 3 - Width (m)	0.39 m
Packaging 4 - Height (m)	1.164 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	8000
Packaging 4 - Type	pallet
Packaging 4 - Volume (m <sup>3</sup> )	1.117 m <sup>3</sup>



Visit the website for your country to get more information and discover our products.

Proceed

**HellermannTyton**

25/03/2024

ETIM 7.0 Key	EC000127
ETIM 8.0 Key	EC000127
ETIM 9.0 Key	EC000127
UNSPSC Key	39121702

© HellermannTyton 2024 (v4.239) | Update: 23/03/2024 | Privacy Settings