



Visit the website for your country to get more information and discover our products.

India

Proceed




# HellermannTyton

25/03/2024

**P-clamp short,  $\text{\O}8.31$  mm,  $D_{\text{min}}=12.7\text{mm}$ ,  
 $D_{\text{max}}=19.5\text{mm}$ ,  $180^\circ$ , black, 280pcs.**

Art.-No. 151-01944 | RCB180SM8SS-  
PA66HIRHSUV/SS304-BK | [Details](#)

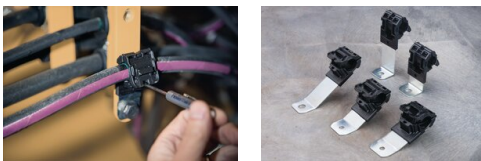

- Ratchet P-Clamp B-Series for bundle diameters from 13.2 mm to 19.5 mm
- One-piece ratchet closure design allows for easy installation during pre- or final assembly



Visit the website for your country to get more information and discover our products.

Proceed

# HellermannTyton

25/03/2024

Easy release feature allows for quick adjustments and maintenance

- Impact modified, heat and UV stabilized PA66 provides long-term durability, in- and outdoors
- Steel mounting plate tolerates high torque mounting and is treated to resist chemicals and salt spray



More products in this product group:

[Ratchet P-Clamp >](#)



Visit the website for your country to get more information and discover our products.

Proceed

**HellermannTyton**

25/03/2024

outdoors. The one-piece adjustable clamp can be closed by hand to the desired diameter. The release feature provides easy and nondestructive removal of cables simply by using a flat-head screwdriver. This nondestructive release allows the clamp to be reused without removing or replacing any bolts or screws. The Ratchet P-Clamp is offered in four sizes and multiple mounting configurations.

Colour	Black (BK)
Fixation Method	Screw Mounting
Key product features	vibration absorbing, removable, releasable, for multiple routing
Material	Polyamide 6.6, high impact modified, heat and UV-stabilised (PA66HIRHSUV), Stainless Steel (SS304)
Pack Cont.	280 pcs.
Package Content packed in	box
PART DESCRIPTION	RCB180SM8SS-PA66HIRHSUV/SS304-BK
Product Family	For bundle diameters from 12.7 mm to 19.5 mm, B-Series
Product Group	Ratchet P-Clamp
Variant	Short




Visit the website for your country to get more information and discover our products.

Proceed

# HellermannTyton

25/03/2024

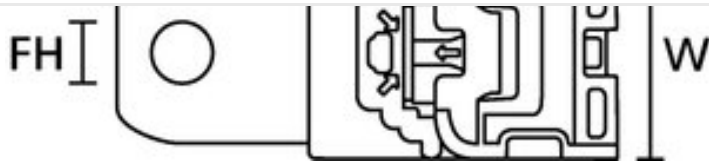

Angle	180 °
Bundle Diameter max (metric)	19.5 mm
Bundle $\varnothing$	12.7-19.5 mm
Bundle $\varnothing$ min.	12.7 mm
Fixing Hole Centres (F)	52.8 mm
Fixing Hole Centres (F)	2.08 "
for Hole $\varnothing$ (FH)	8.31 mm
Length (L)	116.2 mm
Length (L2)	83.1 mm
Min.Tensile Strength	445 N
Strap Width max. (G)	13.2 mm
Strap Width max. (G)	0.52 "
Stud $\varnothing$	M8
Width (W)	34.9 mm
Width (W2)	30.0 mm






Visit the website for your country to get more information and discover our products.

Proceed

# HellermannTyton

25/03/2024

Halogen-free	Yes
Operating Temperature	-40 °C to +105 °C
Plenum Rating	AH-2
Specifications	  
Stamping Material	Stainless Steel (SS304)
UL Listed (US and Canada)	Yes
UL Recognized (US and Canada)	No
UL-File Number	E64139
UV-Stabilised (Yes/No)	Yes

## Logistics and Packaging

Country of Origin	US
GTIN-13 / EAN	4031026578132
Packaging 3 - Height (m)	0.219075 m
Packaging 3 - Length (m)	0.606425 m
Packaging 3 - Type	box
Packaging 3 - Volume (m <sup>3</sup> )	0.0529 m <sup>3</sup>
Packaging 3 - Width (m)	0.3984625 m

## More Information

ETIM 7.0 Key	EC000127
ETIM 8.0 Key	EC000127
ETIM 9.0 Key	EC000127
UNSPSC Key	39121702



Visit the website for your country to get more information and discover our products.

Proceed

**HellermannTyton**

25/03/2024

