

Product data sheet

Specifications



Contactor, Type L, multipole lighting, electrically held, 30A, 10 pole, 600 V, 110/120 VAC 50/60 Hz coil, NEMA 1

8903LG1000V02C

Product availability : Stock - Normally stocked in distribution facility

Main

Product or Component Type	Electrically Held Lighting Contactor
Range of Product	8903L
Control Circuit	Separate control circuit

Complementary

Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Inrush power in VA	180 VA 60 Hz 170 VA 50 Hz
Hold-in power consumption in VA	35 VA 60 Hz 35 VA 50 Hz
Current Rating	20 A tungsten 30 A fluorescent
Number of Poles	10P 10 NO
Control Unit	Selector switch HAND-OFF-AUTO)
Pilot Light	No indicator
Electrical Connection	Screw-clamp terminals
Height	12.68 in (322 mm)
Depth	6.02 in (153 mm)
Width	7.80 in (198 mm)

Environment


Enclosure Type	NEMA 1 painted sheet steel surface
Product Certifications	UL Listed CSA

Ordering and shipping details

Category	21321-8903 L (NOT LX)
Discount Schedule	CP1
GTIN	785901022145

Returnability	No
Country of origin	MX
Packing Units	
Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.30 in (18.542 cm)
Package 1 Width	8.00 in (20.32 cm)
Package 1 Length	13.00 in (33.02 cm)
Package 1 Weight	11.12 lb(US) (5.044 kg)
Offer Sustainability	
Sustainable offer status	Green Premium product
California proposition 65	WARNING: Cancer and Reproductive Harm - www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
PVC free	Yes
Halogen content performance	Halogen free plastic parts product
Contractual warranty	
Warranty	18 months

Approximate Dimensions

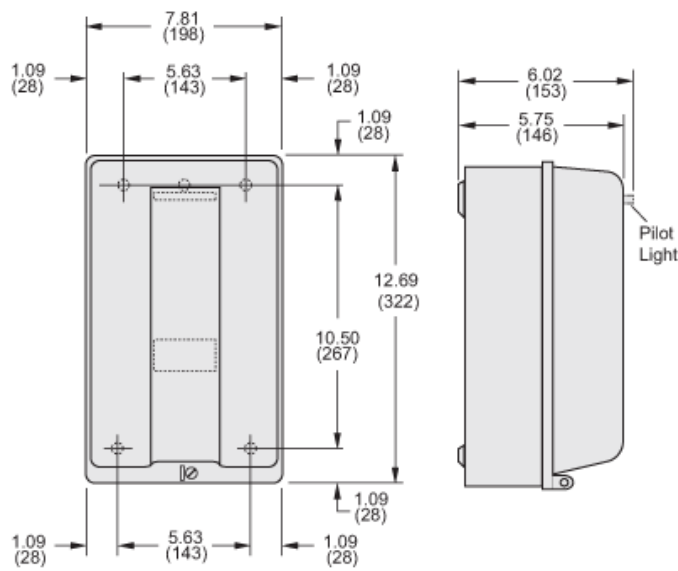

Recommended replacement(s)