

## Main

|                             |                                                                                                                |
|-----------------------------|----------------------------------------------------------------------------------------------------------------|
| Range of product            | Harmony XALD                                                                                                   |
| Product or component type   | Empty control station                                                                                          |
| Device short name           | XALD                                                                                                           |
| Product destination         | For XB5 Ø 22 mm control and signalling units                                                                   |
| Number of cut-out           | 5 cut-outs                                                                                                     |
| Colour of base of enclosure | Light grey RAL 7035)                                                                                           |
| Colour of cover             | Dark grey RAL 7016)                                                                                            |
| Material                    | Polycarbonate                                                                                                  |
| Cable entry                 | 2 knock-outs for cable entry 0.55 in (14 mm)<br>2 knock-outs for Pg 13 cable gland and ISO M20 0.47 in (12 mm) |
| IP degree of protection     | IP66 IEC 60529<br>IP67<br>IP69<br>IP69K                                                                        |

## Complementary

|                                    |                                                                    |
|------------------------------------|--------------------------------------------------------------------|
| Assembly style                     | For customer assembly                                              |
| Number of horizontal rows          | 1                                                                  |
| Number of vertical rows            | 5                                                                  |
| Resistance to high pressure washer | 1015.26 psi (7000000 Pa) 131 °F (55 °C) 0.1 m                      |
| Mounting of block                  | Front mounting<br>Rear mounting                                    |
| Electrical composition code        | SR1<br>MF1<br>MF2<br>SR2<br>SF1<br>PF1<br>PF2<br>SF2<br>MR1<br>PR1 |
| Main group                         | 5 cut-outs                                                         |
| Group of product                   | UL-CSA grey                                                        |

## Environment

|                                       |                            |
|---------------------------------------|----------------------------|
| Protective treatment                  | TH                         |
| Ambient air temperature for storage   | -40...158 °F (-40...70 °C) |
| Ambient air temperature for operation | -40...158 °F (-40...70 °C) |
| Overvoltage category                  | Class II IEC 60536         |
| NEMA degree of protection             | NEMA 13<br>NEMA 4X         |
| IK degree of protection               | IK03 EN 50102              |

|                        |                                                                                                                                         |
|------------------------|-----------------------------------------------------------------------------------------------------------------------------------------|
| Standards              | EN/IEC 60947-5-1<br>EN/IEC 60947-5-5<br>UL 508<br>EN/IEC 60947-5-4<br>JIS C8201-5-1<br>EN/IEC 60947-1<br>CSA C22.2 No 14<br>JIS C8201-1 |
| Product certifications | CSA<br>UL                                                                                                                               |

## Ordering and shipping details

|                   |                       |
|-------------------|-----------------------|
| Category          | 22475 - WALL STATIONS |
| Discount Schedule | CS2                   |
| GTIN              | 00785901115014        |
| Returnability     | Yes                   |
| Country of origin | CZ                    |


## Offer Sustainability

|                            |                                                                                                                                                                                                                                                                       |
|----------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Sustainable offer status   | Green Premium product                                                                                                                                                                                                                                                 |
| California proposition 65  | WARNING: This product can expose you to chemicals including: Lead and lead compounds which is known to the State of California to cause Carcinogen & Reproductive harm. For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a> |
| REACH Regulation           | <a href="#">REACH Declaration</a>                                                                                                                                                                                                                                     |
| REACH free of SVHC         | Yes                                                                                                                                                                                                                                                                   |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>                                                                                                                                                                        |
| Toxic heavy metal free     | Yes                                                                                                                                                                                                                                                                   |
| Mercury free               | Yes                                                                                                                                                                                                                                                                   |
| RoHS exemption information | <a href="#">Yes</a>                                                                                                                                                                                                                                                   |
| China RoHS Regulation      | <a href="#">China RoHS Declaration</a>                                                                                                                                                                                                                                |
| Environmental Disclosure   | <a href="#">Product Environmental Profile</a>                                                                                                                                                                                                                         |
| Circularity Profile        | <a href="#">End Of Life Information</a>                                                                                                                                                                                                                               |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

## Dimensions

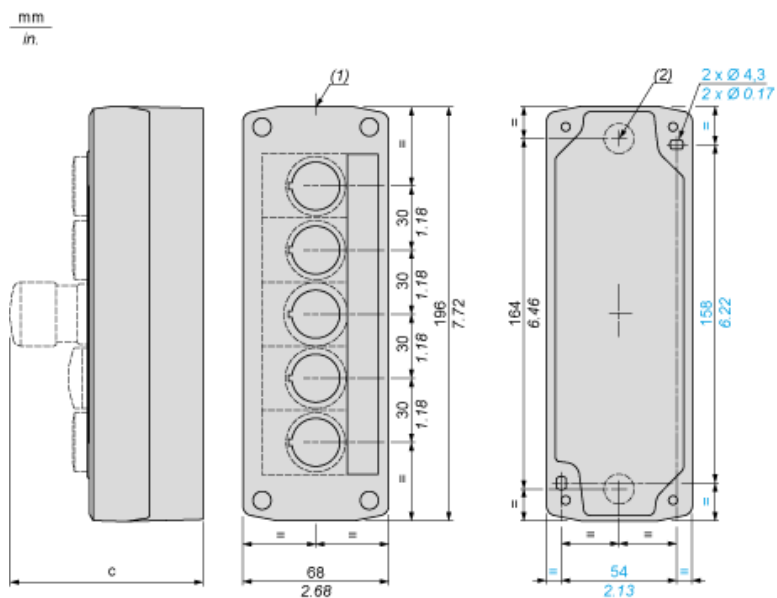

- (1) 2 knock-outs for Pg 13.5 cable gland, maximum capacity 12 mm/0.47 in.  
(2) Knock-out for cable entry, maximum capacity 14 mm/0.55 in.

| Control station fitted with:                              | c in mm | c in in. |
|-----------------------------------------------------------|---------|----------|
| Flush pushbutton                                          | 62      | 2.44     |
| Pilot light                                               | 64      | 2.52     |
| Illuminated pushbutton                                    | 65.5    | 2.58     |
| Projecting pushbutton                                     | 66      | 2.60     |
| Selector switch                                           | 80      | 3.15     |
| Mushroom head pushbutton                                  | 91.5    | 3.58     |
| Latching mushroom head Emergency stop pushbutton with key | 115     | 4.53     |
| Key switch                                                | 105.5   | 4.15     |