

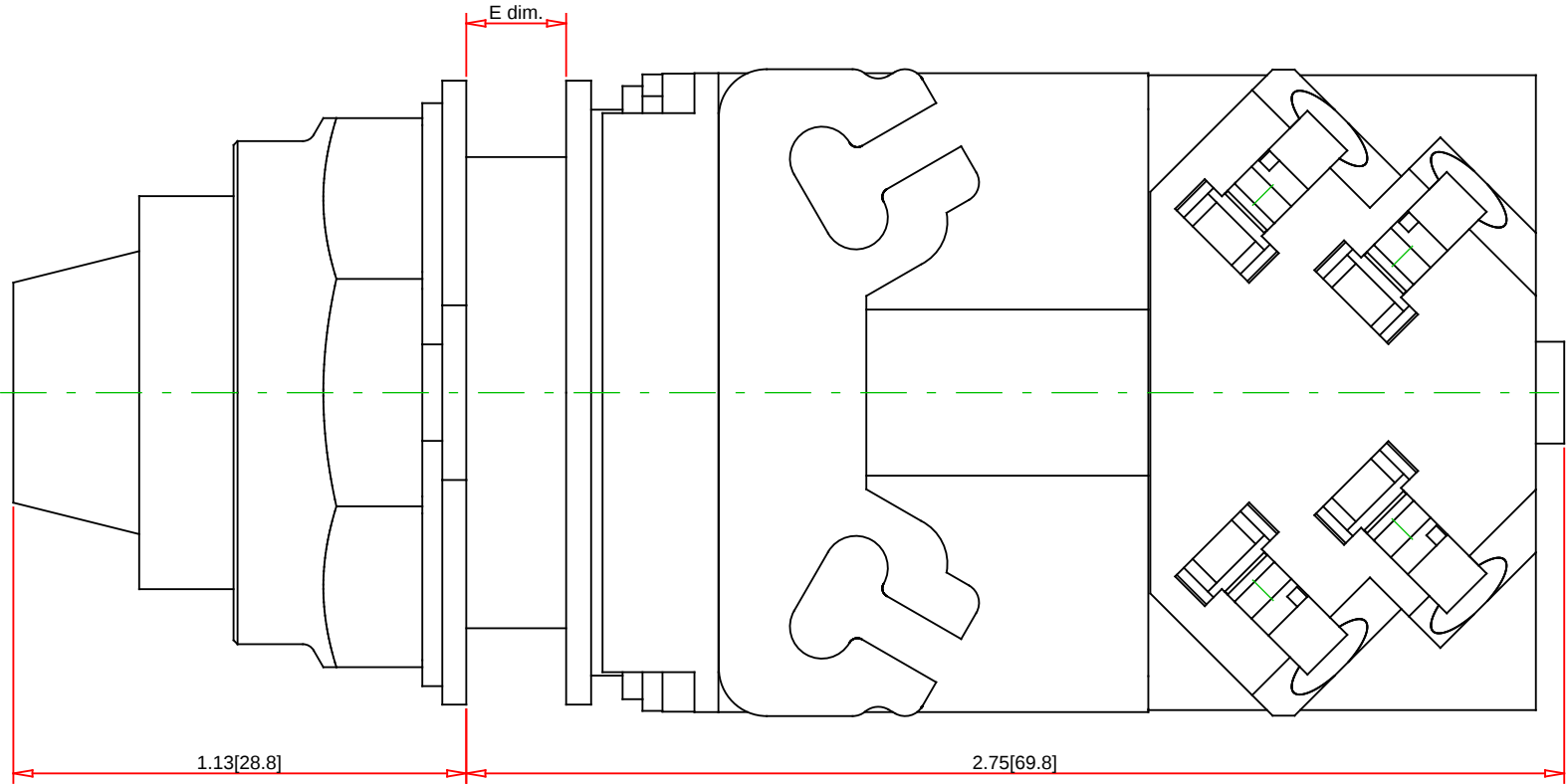


| Panel Thickness<br>E dim.<br>inches (mm) | Number<br>of<br>Gasket |
|------------------------------------------|------------------------|
| 1/16 (1.6)                               | 4                      |
| 1/8 (3.2)                                | 3                      |
| 3/16 (4.8)                               | 2                      |
| 1/4 (6.4)                                | 1                      |

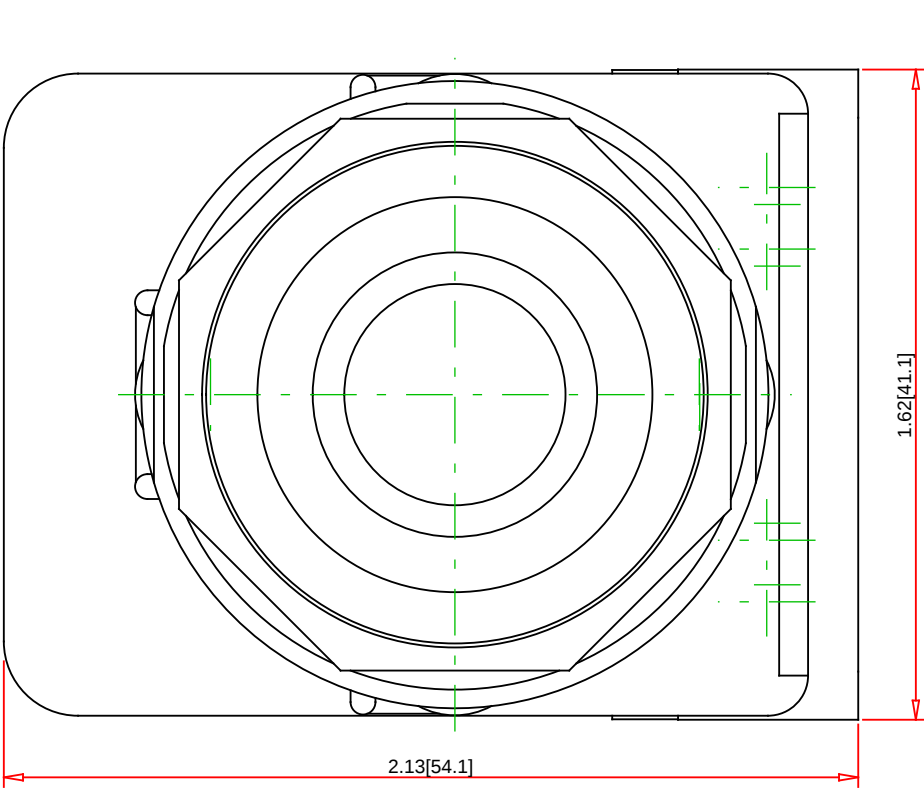

Note:  
- Drawings Not To Scale  
- Drawings Subject to Change Without Notice  
- Dimensions are inches next to [Millimeters]

Part No.:  
  
**9001KT38LYA31**

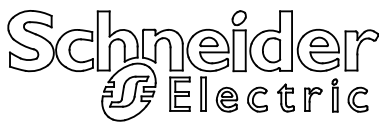

Schneider Electric United States  
North American Division  
Boston One Campus  
800 Federal Street  
Andover, MA 01810, USA  
Phone:+1 8773425173  
Email: CCC@us.schneider-electric.com

| Technical Information:       |                                                                                      |
|------------------------------|--------------------------------------------------------------------------------------|
| UL File:                     | E78403 CCN NKCR                                                                      |
| CSA File:                    | LR24590 Class 3211-03                                                                |
| CE Marked:                   | Yes                                                                                  |
| RoHS:                        | Yes                                                                                  |
| NEMA / IP Rating:            | NEMA 1/2/3/3R/4/6/12/13 Water tight, Dust tight and Oil tight (Indoor/Outdoor), IP66 |
| Key Number:                  | n/a                                                                                  |
| Key Removal:                 | n/a                                                                                  |
| Light Module Supply Voltage: | 120V                                                                                 |
| Light Module Type:           | LED (Yellow)                                                                         |
| Number of Operators:         | n/a                                                                                  |

| Specification:       |                      |
|----------------------|----------------------|
| Description:         | 30mm Pilot Light     |
| Ring Nut Material:   | Chromium Plated Zinc |
| Operator Type:       | Push-To-Test         |
| Operator Action:     | n/a                  |
| Button Type:         | n/a                  |
| Guard Type:          | n/a                  |
| Button/Cap Color:    | n/a                  |
| Lens Type:           | Plastic (Fresnel)    |
| Lens Color:          | Amber                |
| Knob Type:           | not applicable       |
| Knob Color:          | n/a                  |
| Number of Positions: | n/a                  |