

# Product data sheet

Specifications



Complete beacon, Harmony XVB Universal, 70mm, integral LED, steady, red, IP65/66, 120V AC

XVBL0G4

Product availability : Stock - Normally stocked in distribution facility

## Main

Range of Product	Harmony XVB Universal
Product or Component Type	Complete beacon
Beacon or indicator bank unit type	Base unit direct or tube fixing Illuminated unit
Signalling type	Steady
Mounting diameter	2.76 in (70 mm)
Component name	XVBL
Material	Glass reinforced polyamide base unit Polycarbonate illuminated unit
Light source	Integral LED, red
Bulb type	Protected LED
[Us] rated supply voltage	120 V AC

## Complementary

Connections - terminals	Screw clamp terminals, <= 1 x 1.5 mm² with cable end
[Ui] rated insulation voltage	250 V IEC 60947-1
Nominal voltage limit	0.85...1.1 Un IEC 60947-5-1
Current consumption	< 17 mA AC
[Uimp] rated impulse withstand voltage	4 kV IEC 60947-1
CAD overall width	2.76 in (70 mm)
CAD overall height	5.47 in (139 mm)
CAD overall depth	2.76 in (70 mm)
Terminals description ISO n°1	(GND)GROUND (COM-1)PW
Net Weight	0.60 lb(US) (0.27 kg)

## Environment

Pollution degree	2
Product Certifications	CCC EAC CSA C22-2 No 14

	UL 508
Standards	EN/IEC 60947-5-1
Protective treatment	TC
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Electrical shock protection class	Class I on support tube IEC 61140 Class II on base unit IEC 61140
IP degree of protection	IP65 on fixing base XVBZ0. IEC 60529 IP66 on base unit IEC 60529
NEMA degree of protection	Type 4X UL indoor)

### Ordering and shipping details

Category	22611-XVB-STACKLIGHTS
Discount Schedule	XV
GTIN	3389110844436
Returnability	No
Country of origin	CZ

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.71 in (14.5 cm)
Package 1 Width	3.15 in (8.0 cm)
Package 1 Length	3.15 in (8.0 cm)
Package 1 Weight	9.49 oz (269.0 g)
Unit Type of Package 2	S03
Number of Units in Package 2	18
Package 2 Height	11.81 in (30.0 cm)
Package 2 Width	11.81 in (30.0 cm)
Package 2 Length	15.75 in (40.0 cm)
Package 2 Weight	11.70 lb(US) (5.309 kg)

### Offer Sustainability


Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

Contractual warranty

Warranty	18 months
----------	-----------

Illuminated Beacon for BA 15d Bulb or LED


Dimensions

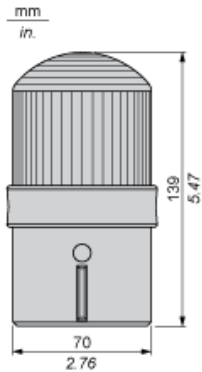

Illuminated Beacon

---

Wiring Diagram

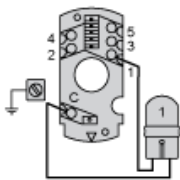

Recommended replacement(s)