

# Product data sheet

Specifications



Pilot light, Harmony XVL, plastic, red, 8mm, covered LED, faston connectors, 12V DC

XVLA224

Product availability : Stock - Normally stocked in distribution facility

## Main

Range of Product	Harmony XVL
Product or Component Type	LED pilot light with integral lens cap
Component name	XVL
Mounting diameter	0.31 in (8 mm)
Light source	Covered LED
Light block colour	Red
Protection Type	Integral ballast resistor Built-in by diode
[Us] rated supply voltage	12 V
IP degree of protection	IP65 IEC 60529 with seal XVLZ911) IP65 NF C 20-010 with seal XVLZ911) IP40 IEC 60529 IP40 NF C 20-010

## Complementary

Supply circuit type	DC
Connections - terminals	Tag for Faston connectors 2.8 x 0.5 mm Tag for soldering connectors
Current Consumption	18 mA
[Ui] rated insulation voltage	50 V IEC 60947-1
Bulb lifespan	100000 h
Nominal voltage limit	0.8...1.1 Un
Terminals description ISO n°1	(X1-X2)PL
Height	0.39 in (10 mm)
Width	0.39 in (10 mm)
Depth	1.42 in (36 mm)
Net Weight	0.01 lb(US) (0.003 kg)

## Environment

Product Certifications	CSA UL
Protective treatment	TC

Ambient Air Temperature for Operation	-13...158 °F (-25...70 °C)
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Overvoltage category	Class 3 IEC 60536 Class 3 NF C 20-030

### Ordering and shipping details

Category	22460-PUSHBUTTONS 22MM (PLASTIC)
Discount Schedule	CS2
GTIN	3389110651324
Returnability	No
Country of origin	FR

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	0.59 in (1.5 cm)
Package 1 Width	0.75 in (1.9 cm)
Package 1 Length	2.87 in (7.3 cm)
Package 1 Weight	0.11 oz (3.0 g)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	1.18 in (3.0 cm)
Package 2 Width	5.12 in (13.0 cm)
Package 2 Length	5.12 in (13.0 cm)
Package 2 Weight	1.13 oz (32.0 g)
Unit Type of Package 3	S01
Number of Units in Package 3	100
Package 3 Height	5.91 in (15.0 cm)
Package 3 Width	5.91 in (15.0 cm)
Package 3 Length	15.75 in (40.0 cm)
Package 3 Weight	18.77 oz (532.0 g)

### Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>


WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.
------	--

Contractual warranty

Warranty	18 months
----------	-----------

LED Pilot Light

Dimensions

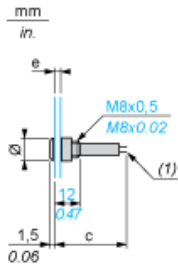


(1) Tags for Faston connectors or soldered connections  
e panel thickness: 1 to 8 mm/0.03 to 0.31 in.

C		Ø	
mm	in.	mm	in.
34	1.34	10	0.39

LED Pilot Light

Panel Drilling

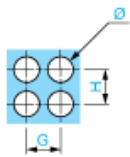

Ø min		G min		H min	
mm	in.	mm	in.	mm	in.
8.2	0.32	10.5	0.41	10.5	0.41

Recommended replacement(s)