

Product data sheet

Specifications



plug-in solid state relay - 12.5 mm -
output - 5..48 V DC - 2 A

ABS7SC3E

Product availability : Stock - Normally stocked in distribution facility

Main

Range of Product	Advantys Telefast ABE7
Product or Component Type	Plug-in solid state relay
Relay Type	Output relay
Minimum ordered quantity	Set of 4

Complementary

Response time	<= 0.1 ms from state 0 to 1 <= 0.6 ms from state 1 to 0
Width pitch dimension	0.47 in (12 mm)
Product Compatibility	ABE7R16T332 ABE7P16T330E ABE7P16T330 ABE7P16T318 ABE7R16T330 ABE7P16T334 ABE7P16T318E
Discrete input voltage	24 V DC
Discrete output voltage	5...48 V DC
Discrete output current	1500 mA
Current state 0 guaranteed	0.4 mA DC
Current state 1 guaranteed	2.9 mA DC
Voltage state 0 guaranteed	3.8 V DC
Voltage state 1 guaranteed	18.6 V DC
Net Weight	0.04 lb(US) (0.016 kg)

Ordering and shipping details

Category	22375-INTERFACE MODULE(ABA,R,S)
Discount Schedule	CP2
GTIN	3389110720778
Returnability	No
Country of origin	LV

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.97 in (5.0 cm)
Package 1 Width	2.05 in (5.2 cm)
Package 1 Length	2.56 in (6.5 cm)
Package 1 Weight	0.53 oz (15.0 g)
Unit Type of Package 2	BB1
Number of Units in Package 2	4
Package 2 Height	1.97 in (5.0 cm)
Package 2 Width	2.05 in (5.2 cm)
Package 2 Length	2.56 in (6.5 cm)
Package 2 Weight	2.15 oz (61.0 g)
Unit Type of Package 3	S01
Number of Units in Package 3	64
Package 3 Height	5.91 in (15.0 cm)
Package 3 Width	5.91 in (15.0 cm)
Package 3 Length	15.75 in (40.0 cm)
Package 3 Weight	2.64 lb(US) (1.198 kg)

 
Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration
Environmental Disclosure	Product Environmental Profile
PVC free	Yes


Contractual warranty

Warranty	18 months
----------	-----------

Internal Wiring Diagram



Temperature Derating Curves

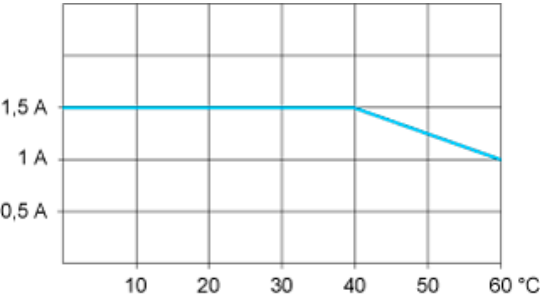

Recommended replacement(s)