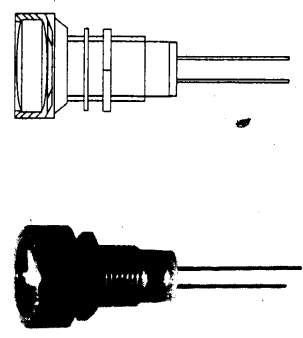
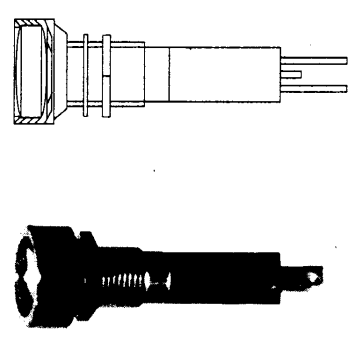


Led Signalleuchten Einbaudurchmesser 8 mm
Led Indicators Body diameter 8 mm

Superhell, mit Optik
Superbright, with reflecting mirror+ lens

Bestell-Nr. Part No.	Farbe Colour	V _{OP} +10% (V)	I _{OP max.} (mA)	V _F (V)	I _{V typ.} (mcd) *I _F = 20mA	I _{F max.} (mA)	Abb. Illu.	Abmessungen, siehe Zeichnungsnr. Dimensions, see Drawing No.	19180-A	A
19180000	Super rot Super red			2,0/2,8	*100	30	A			
19180001	Grün Green			2,2/2,8	*150	30	A			
19180002	Gelb Yellow			2,1/2,8	*200	30	A			
19180003	Hyper rot Hyper red			1,9/2,5	*350	30	A			
19180050	Super rot Super red			2,0/2,8	*100	30	C			
19180051	Grün Green			2,2/2,8	*150	30	C			
19180052	Gelb Yellow			2,1/2,8	*200	30	C			
19180053	Hyper rot Hyper red			1,9/2,5	*350	30	C			
19180150	Super-rot Super red	6	30		130		B	Abmessungen, siehe Zeichnungsnr. Dimensions, see Drawing No.	19180-B	B
19180151	Grün Green	6	30		220		B			
19180152	Gelb Yellow	6	30		290		B			
19180153	Hyper rot Hyper red	6	30		1000		B			
19180250	Super rot Super red	12	30		130		B			
19180251	Grün Green	12	30		220		B			
19180252	Gelb Yellow	12	30		290		B			
19180253	Hyper rot Hyper red	12	30		1000		B			
19180350	Super rot Super red	24	22		110		B			
19180351	Grün Green	24	22		160		B			
19180352	Gelb Yellow	24	22		220		B	19180050 - 19180053, wird als verkürzte Ausführung mit Steckkontakten geliefert, siehe Zeichnung Nr. 19180-C 19180050 - 19180053, short version with tabs, see drawing no. 19180-C	C	
19180353	Hyper rot Hyper red	24	22		370		B			

**Lieferbar auch als blinkende oder zwei- und drei-
 farbige Led Signalleuchten.**

**Available also as flashing or two- and three co-
 loured Led Indicators.**

Arbeitstemperatur (T_{OP}): -55°C - +70°C
 Lagertemperatur (T_{STG}): -55°C - +100°C

Operating temperature (T_{OP}): -55°C - +70°C
 Storage temperature (T_{STG}): -55°C - +100°C

Nur in Glanzchrom lieferbar

Available in bright chrome only

Led Signalleuchten mit anderen Spannungen auf Anfrage
 Technische Änderungen vorbehalten

Led Indicators with other voltages upon request
 Specification subject to change without notice