


Product data sheet

Specifications

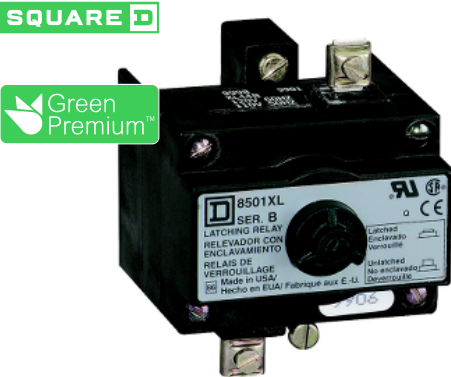

NEMA Control Relay, Type X, mechanical latch attachment, 110/120VAC 50/60Hz coil

8501XLV02

Product availability : Stock - Normally stocked in distribution facility

Main

Range of Product	8501X
Relay Type	Control relay
Product or Component Type	Latching device

Complementary

[Uc] control circuit voltage	110 V AC 50 Hz 120 V AC 60 Hz
Coil Voltage Limits	Operational 0.85...1.1 Uc AC 50/60 Hz
Coil Inrush Power	148 VA 60 Hz 143 VA 50 Hz
Coil Sealed Power	23 VA 60 Hz 25 VA 50 Hz
Electrical Connection	Screw clamp terminals
Wire Gauge	AWG 18...AWG 12 copper
Terminal Tightening Torque	Control circuit 9.03...12.04 lbf.in (1.02...1.36 N.m) screw terminals
Height	2.87 in (73 mm)
Width	2.24 in (57 mm)
Depth	2.95 in (75 mm)
Net Weight	0.76 lb(US) (0.3425 kg)

Environment

Product Certifications	UL recognized E78403 CCN NKCR2 CE CSA LR60905 class 3211 02
------------------------	---

Ordering and shipping details

Category	21159-8501 X ACCESSORIES
Discount Schedule	CP2
GTIN	785901028475
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.00 in (7.62 cm)
Package 1 Width	3.40 in (8.636 cm)
Package 1 Length	4.30 in (10.922 cm)
Package 1 Weight	14.24 oz (403.697 g)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)