

Product data sheet

Specifications



Mini circuit breaker, QO, 15A, 2 pole, 120/240VAC, 10kA, plug in mount, ring terminals

QO215H5237

Product availability : Stock - Normally stocked in distribution facility

Main

Product	Miniature circuit-breaker
Range	QO
Current Rating	15 A
Voltage Rating	120/240 V AC 240 V AC 120 V AC
Mounting Type	Plug-in
Number of Poles	2P
Circuit Breaker Type	Standard
Ratings	HACR rated
Electrical Connection	Ring tongue

Complementary

Interrupt Rating	10 kA 120/240 V AC 50/60 Hz 10 kA 240 V AC 50/60 Hz 10 kA 120 V AC 50/60 Hz
Number of Panel Spaces	2
Wire Size	AWG 14...AWG 8 copper
Tightening Torque	40.71 lbf.in (4.6 N.m)
Height	2.99 in (76 mm)
Width	1.50 in (38 mm)
Depth	2.91 in (74 mm)
Net Weight	1.00 lb(US) (0.454 kg)

Environment

Certifications	UL Listed CSA
Ambient Rating	104 °F (40 °C)

Ordering and shipping details

Category	00926-QO IND SPECIALTY CB
Discount Schedule	DE2A

GTIN	785901126713
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.99 in (7.6 cm)
Package 1 Width	1.50 in (3.8 cm)
Package 1 Length	2.91 in (7.4 cm)
Package 1 Weight	16.00 oz (453.592 g)

Offer Sustainability


REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.

Product data sheet

Technical Illustration

Q0215H5237

Dimensions

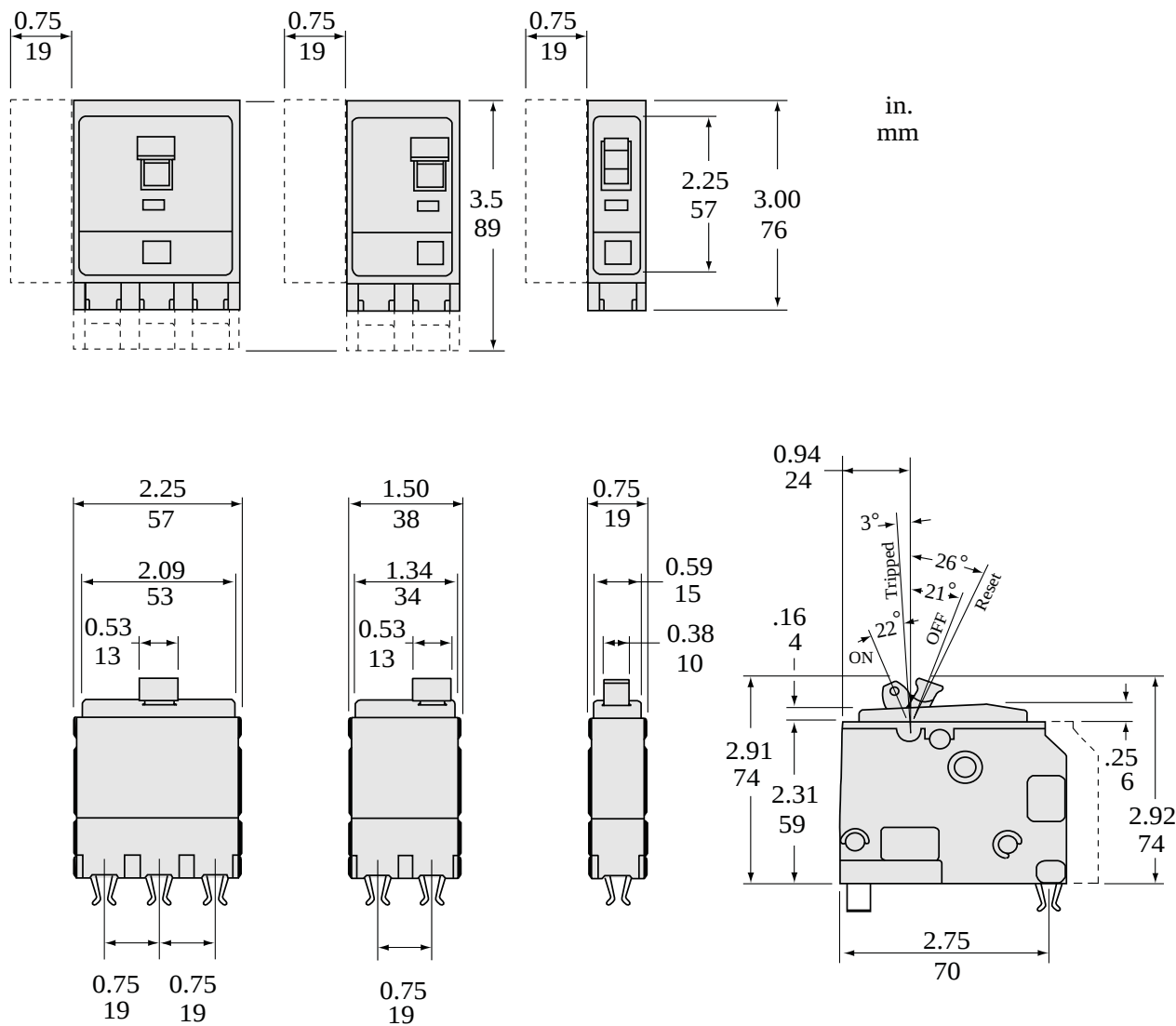

Dimensions are approximate. Refer to technical documentation, dimension drawings, and/or CAD for additional detail.

Recommended replacement(s)