




# BU-41500310XX

(Cable Assembly Coaxial SMA Female Bulkhead to SMA Straight Male RG-316)

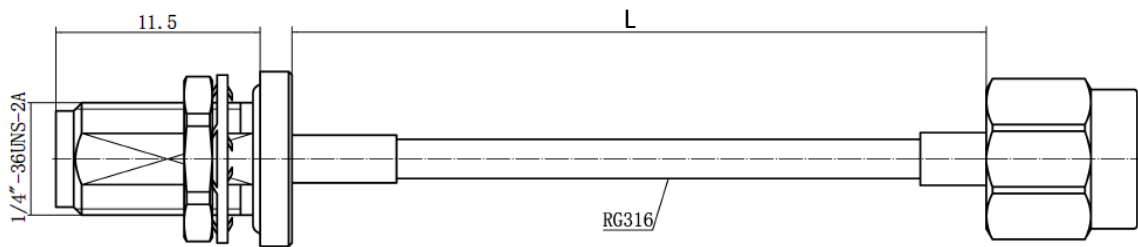

Mueller Electric Company  
2850 Gilchrist Rd. Bld 5A  
Akron, OH 44305

[www.muellerelectric.com](http://www.muellerelectric.com)

Toll Free: 800.955.2629  
Phone: 330.780.2525  
Fax: 330.780.2524

## Electrical Ratings

Electrical ratings of a cable assembly are determined by the limiting connector type and cable size.

Connector	Cable	Connector Impedance (Ohms)	Frequency (GHz)	VSWR	Working Voltage (At Sea Level)
SMA	RG-316	50	0-6	1.25 MAX	335V

### Product Attributes

Gender	Male to Male
Style	SMA to SMA
1st Connector	Gold Plated SMA Female Bulkhead
2nd Connector	Gold Plated SMA Male Plug
Features	Shielded
Operating Temperature	-65°C (-85°F) to 150°C (302°F)
BU-4150031006	6" (152.40 mm)
BU-4150031012	12" (304.8 mm)
BU-4150031018	18" (457.2 mm)
BU-4150031024	24" (609.6 mm)
BU-4150031036	36" (914.4 mm)
BU-4150031048	48" (1219.2 mm)
BU-4150031M1.0	1M (39.4")
BU-4150031M1.5	1.5M (59.1")
BU-4150031MM150	150mm (5.9")
BU-4150031MM250	250mm (9.8")
BU-4150031MM500	500mm (19.7")
BU-4150031MM750	750mm (29.5")
RoHS 3 Compliant	