


SPECIFICATIONS

PARAMETERS	VALUES	UNITS
Rated Voltage	5	Vdc
Operating Voltage	4 ~ 7	Vdc
Rated Current (max.)	30	mA
Typical Sound Pressure Level @ 10 cm.	85	dBA
Output Frequency	2300±300	Hz
Operating Temperature Range	-40 ~ +85	°C
Storage Temperature Range	-40 ~ +85	°C
Housing Material	SEI-GFN2J	
Terminal	Tin-Plated Copper Pins	
Weight	7	g

REVISIONS

LTR	DESCRIPTION	DATE	APPROVED
-	RELEASED FROM ENGINEERING	6/23/99	
A	ADDED ELECTRICAL SPECIFICATION	06/07/02	S. J.

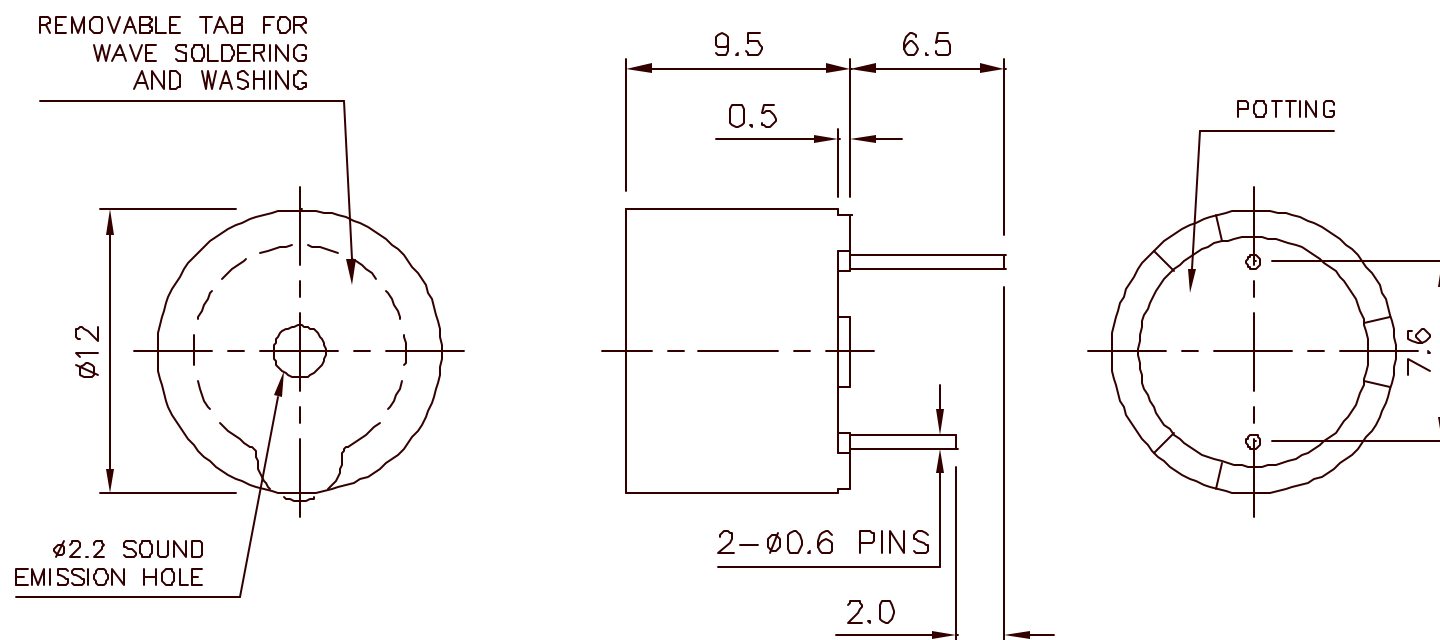

NOTES:

1. ALL DIMENSIONS ARE IN MILLIMETERS.
2. SPECIFICATION SUBJECT TO CHANGE OR WITHDRAWAL WITHOUT NOTICE.

DRAWING NAME
AI155

UNLESS OTHERWISE SPECIFIED
DIMENSIONS ARE IN MILLIMETERS
TOLERANCES ARE:
FRACTIONS DECIMALS ANGLES
± .XX ± 0.5 ±
XXX ±

APPROVALS	DATE
DRAWN TMM	6/99
CHECKED	
APPROVED S. J.	06/23/99
DO NOT SCALE DRAWING	



projects[®]
unlimited

Dayton, Ohio

ELECTRO-MECH. AUDIO INDICATOR
AI-155

SIZE A	MATERIAL	DRAWING NO. AI155.DWG
NOT TO SCALE	MAX. WT.	SHEET 1 OF 1