

IN 30 LKM Screwdriver bit socket set 10 pieces

For hexagon head screws (INBUS®), in plastic case.

© = reg. trademark of Bauer & Schaurte

Code	No.	Contents	
1509918	IN 30 LKM	● IN 30 4 5 6 8 10 ● IN 30 L 4 5 6 8 10	




ITX 30 PM Screwdriver bit socket set 7 pieces

For recessed TORX® screws, in blue sheet steel case.

© = reg. trademark of Camcar-Textron Inc. USA

Code	No.	Contents	
1509926	ITX 30 PM	● ITX 30 T20 T25 T27 T30 T40 T45 T50	

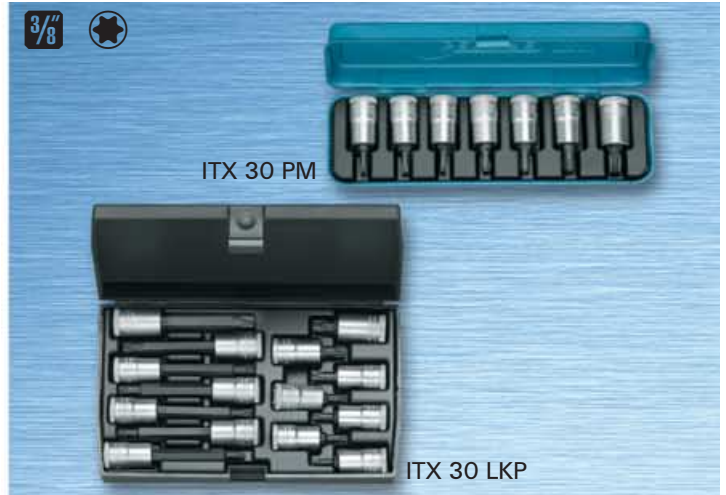

ITX 30 LKP Screwdriver bit socket set 14 pieces

For recessed TORX® screws, short and long, in plastic case.

© = reg. trademark of Camcar-Textron Inc. USA

Code	No.	Contents	
1509950	ITX 30 LKP	● ITX 30 T20 T25 T27 T30 T40 T45 T50 ● ITX 30 L T20 T25 T27 T30 T40 T45 T50	

ITX 30 TX Screwdriver bit socket set 15 pieces

For protruding and recessed TORX® screws, in plastic case.

© = reg. trademark of Camcar-Textron Inc. USA

Code	No.	Contents	
1509942	ITX 30 TX-015	● ITX 30 T20 T25 T27 T30 T40 T45 T50 ○ TX 30 E5 E6 E7 E8 E10 E11 E12 E14	



TX 30 Screwdriver bit socket set 8 pieces

For protruding TORX® screws, in GEDORIT blue sheet steel case.

© = reg. trademark of Camcar-Textron Inc. USA

Code	No.	Contents	
1509934	TX 30 E-08	○ TX 30 E5 E6 E7 E8 E10 E11 E12 E14	

30 TX Screwdriver bit socket set 28 pieces

For protruding and recessed TORX® screws, in plastic case.

© = reg. trademark of Camcar-Textron Inc. USA

Code	No.	Contents	
1509969	30 TX-20	<ul style="list-style-type: none"> ● ITX 30 T25 T27 T30 T40 T45 T50 ● ITX 30 L T20 T25 T27 T30 T40 T45 T50 ○ TX 30 E8 E10 E11 E12 E14 ● ITX 20 T8 T9 T10 T15 T20 ○ TX 20 E4 E5 E6 E7 <p style="text-align: right;">2030</p>	



VB 30 Display box

For 228 sockets 3/8" square drive. Best selling sizes, easily accessible. Modern attractive shape. Sheet steel, in GEDORIT blue stove enamelled. Dimensions: 430 x 300 x 220 mm.

Code	No.	Execution	Contents	
6233500	VB 30	○ 30	Display box with tool assortment consisting of: 12 pieces each 10 13 mm 10 pieces each 6 7 8 9 mm 8 pieces each ● IN 30 5 3019 11 12 14 15 17 19 mm 5 pieces each ● IN 30 4 6 16 18 20 21 22 mm	16.0
6233690	VBD 30	⊕ D 30	● IS 30 5.5 8 10 ⊕ IKS 30 1 2 3 ● IN 30 8 10 ● INX 30 5 6 8	16.0
5231940	VB 30 L		Display box empty	4.0

