


This information is given as an indication. In the continual goal to improve our products, we reserve the right to make any modifications judged necessary



**DRAWING**

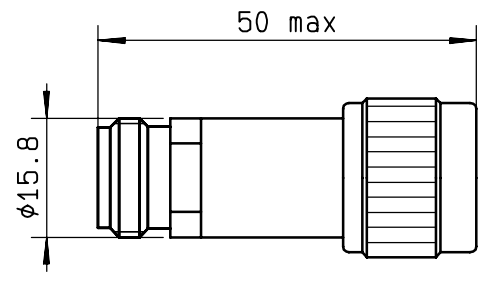

General tolerances: +/- 0.5 mm

**R F CHARACTERISTICS**

FREQUENCY RANGE : DC - 2 GHz  
 IMPEDANCE : 50 Ohms  
 ATTENUATION - NOMINAL : 10 dB

FREQUENCY	DC- 2 GHz
V.S.W.R	<= 1.15
DEVIATION (dB)	+0.35 / - 0.35

PEAK POWER at 25°C (1µs,1%.) : 100 W  
 AVERAGE POWER at 25°C : 2 W


**MECHANICAL CHARACTERISTICS**

CONNECTORS : N male/female per MIL-C 39012  
 WEIGHT : < 60 g

**ENVIRONMENTAL CHARACTERISTICS**

OPERATING TEMPERATURE RANGE (°C) : -55 , +125  
 STORAGE TEMPERATURE RANGE (°C) : -55 , +125

Power derating  
Versus temperature

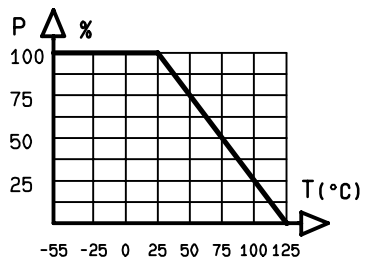

CREATION				
N° :				
PEN/EP:CAT				
Name:MG				
Date:26. apr. 95				
APP.:AF				
ISSUE		REVISIONS		NAME APPR.