


FARNELL INONE 3721735 4.565000

F-G 40x40

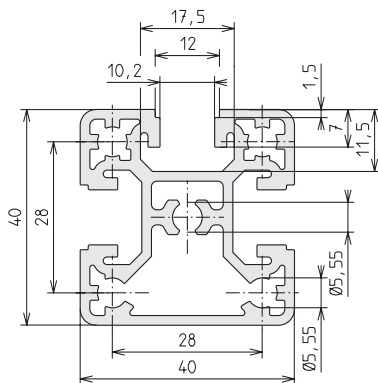

Fläche surface 579 mm²
 I 9,4 cm⁴
 I_t 19,0 cm⁴
 W 4,5 cm³
 Gewicht weight 1563 g/m



Code No.	Profil F-G 40x40	Profile F-G 40x40	Eloxal	Anod. coating
4.545000	Zuschnitt cut	max. 6000 mm	hell	natural
4.545001	Stange bar	à 6000 mm	hell	natural



Anschluss
 1 lange Flanschleiste
 Connection
 1 long flange bracket



Anschluss
 1 kurze Flanschleiste
 Connection
 1 short flange bracket




Anschluss
 1 Flanschnutenstein -N-
 Connection
 1 flange slot stone -N-

benötigte Menge je Verbindung required qty per connection	Code No. /Stück pcs	Flanschleiste Flange bracket	Nutgeometrie Slot geometry	Anschluss Connection
1 Stück piece	4.816703	40	30	lang long
1 Stück piece	4.816702	40	40	lang long
1 Stück piece	4.566700	40 (K)	30	kurz short
1 Stück piece	4.566701	40 (K)	40	kurz short
1 Stück piece	4.546700	40 (N)	40	Flanschnutenstein -N- flange slot stone -N-

F-GG 40x40



Fläche surface 562 mm²
 I 9,5 cm⁴
 I_t 18,9 cm⁴
 W 4,6 cm³
 Gewicht weight 1516 g/m

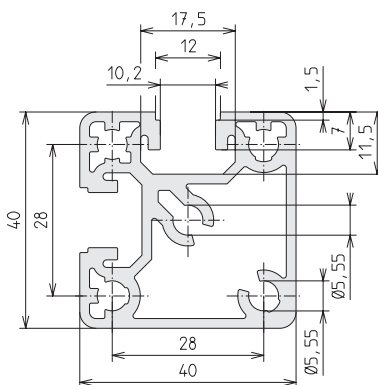

Code No.	Profil F-GG 40x40	Profile F-GG 40x40	Eloxal	Anod. coating
4.565000	Zuschnitt cut	max. 6000 mm	hell	natural
4.565001	Stange bar	à 6000 mm	hell	natural



Anschluss
 1 kurze Flanschleiste
 Connection
 1 short flange bracket



Anschluss
 1 Flanschnutenstein -N-
 Connection
 1 flange slot stone -N-

benötigte Menge je Verbindung required qty per connection	Code No. /Stück pcs	Flanschleiste Flange bracket	Nutgeometrie Slot geometry	Anschluss Connection
1 Stück piece	4.566700	40 (K)	30	kurz short
1 Stück piece	4.566701	40 (K)	40	kurz short
1 Stück piece	4.546700	40 (N)	40	Flanschnutenstein -N- flange slot stone -N-