



H1 SERIES | H12WD

PANEL MOUNT



Features

- Ratings from 25A to 125A
- Low off-state leakage current
- SCR output for heavy industrial applications
- Zero Voltage or instantaneous turn-off
- UL/CSA/TUV Approved, CE Marked
- Improved SEMS screw assembly
- Redesigned housing with improved heat dissipation
- DC control
- Direct bond copper substrate
- EMC Compliant to Level 3
- Direct power lead frame
- Epoxy free design

For **Generation 3** datasheet




PRODUCT SELECTION

Control Voltage	25A	50A	75A
4-32 VDC	H12WD4825	H12WD4850	H12WD4875



ORDERING OPTIONS

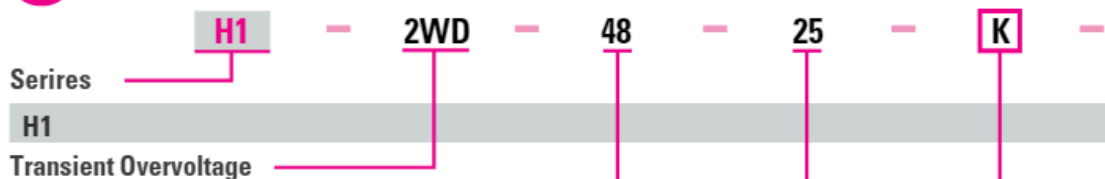

2WD: 1200 Vpk
sensata-h1-series-h12wd-ac-panel-mou...
48-48-600 VAC

Navigation icons: minus, plus, download, refresh