

Actuator

46-
2W28.3CV0.001

Distribution by
Newark



<https://newark.eao.com/p/46-2W28.3CV0.001>

Your product:



46-2W28.3CV0.001 Actuator

FRONT

Front bezel colour:	Silver
Front dimension:	Ø 30 mm
Front bezel material:	Metal
Front form:	round

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lever shape:	short
Lever bar colour:	Black
Lever colour:	White
Lever material:	plastic

ELECTRICAL CHARACTERISTICS

Protection class:	II
-------------------	----

MECHANICAL CHARACTERISTIC

Switching positions:	2 positions
Switching action:	Maintained - Maintained
Switching angle:	90°

Weight: 0.038 kg

Mechanical lifetime: 1 Mio. cycles of operation

Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

AMBIENT CONDITION

IP front protection: IP65

Operating temperature: – 25 °C ... + 55 °C

Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

IK front protection: IK03

CERTIFICATE

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

Conformities: CE

OTHER


Housing material: Plastic

Housing colour: Black

Short Description: Actuator, Ø 22.3 mm, Ø 30 mm, illuminative, White, short, round, Silver, Metal, Maintained - Maintained, IP65, IK03

max. number of switching elements: 2

Dimension drawings:

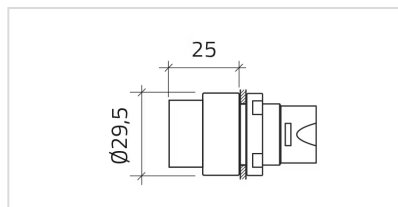

Switching positions:

