



S10 4-65W SIN 220-240V WH EUR

Product family description

Range of premium-quality glow switch starters for igniting fluorescent lamps with electromagnetic ballast.

Product Features

- Redesigned canister top with 2 installation notches into which the pins of another starter fit perfectly (patented innovation)
- Radioactive-free (patented) and lead-free (RoHS-compliant)
- Premium reliability with 10,000 safe switches
- 2-pin igniter in plastic (flame-retardant polycarbonate) canister with high-quality radio-interference suppression capacitor
- Well-defined preheat and peak voltage ensure proper ignition

Product Benefits

- The only starter that offers fast, easy installation with no need to use any extra tools
- No irritation – even firmly stuck starters can be removed easily
- Eco-friendly, recyclable concept (free of lead and radioactivity)
- More than 25% longer lamp life; lower maintenance costs compared with lower-quality, non-IEC-compliant starters
- Optimal connectivity through brass components and oxidation-resistant brass pins
- Flame-retardant components and UV-resistant canister for additional safety and secure ignition (validated by Underwriters Laboratories UL)

Application

- Ignite fluorescent lamps of all brands with conventional electromagnetic ballast using TL-D (T8), TL (T12), TL mini and PL-L lamps
- S2 Ecoclick starters are suitable for:

PHILIPS


- S10 Ecoclick starters are suitable for 220/240V, 4-65W single applications
- S10 Ecoclick starter is required for 220/240V, 13W single application
- S2 Ecoclick starter is recommended for 220/240V, 18W single application for optimum performance
- 110/130V, 4-22W single applications
- 220/240V, 4-6-8-15-18-22W single applications
- 220/240V, 4-22W series applications

Product data	
Order code	697691 31
Full product code	871150069769131
loccod	
Full product name	S10 4-65W SIN 220-240V WH EUR
Order product name	S10 4-65W SIN 220-240V WH EUR/20X10CT
Packing type	
Pieces per pack	1
Packing configuration	20X10CT
Packs per outerbox	200
Bar code on pack - EAN1	8711500697691
Bar code on intermediate packing - EAN2	8711500697899
Bar code on outerbox - EAN3	8711500697905
Logistic code(s) - I2NC	9283 922 20238
ILCOS code	
Net weight per piece	7.000 GR
Successor order code	
System Description	Single
Colour of the Housing	
Execution	White
Lamp Wattage	4-65W
Voltage	220-240V
Non Reclosure Voltage	140 V



STARTER S10 EUR

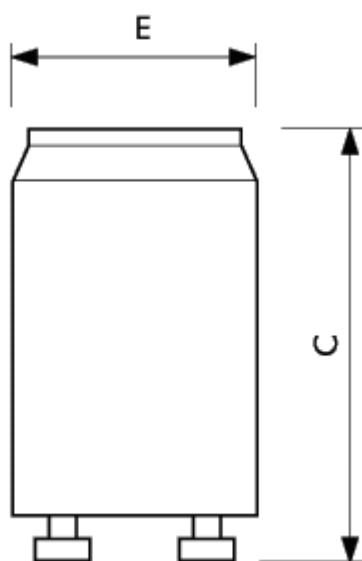


STARTER S10/S10E/S2/S2E

	C	E
Full product name	Max	Max
S10 4-65W SIN 220-240V WH EUR	40.3	21.5



©2009 Koninklijke Philips Electronics N.V.

All rights reserved. Reproduction in whole or in part is prohibited without the prior written consent of the copyright owner. The information presented in this document does not form part of any quotation or contract, is believed to be accurate and reliable and may be changed without notice. No liability will be accepted by the publisher for any consequence of its use. Publication thereof does not convey nor imply any license under patent- or other industrial or intellectual property rights.

Document order number : 0000 000 00000