




**9031P**

**ERGO™ Central Nut Reversible  
Extra Wide Opening Jaw  
Adjustable Wrenches with Rubber  
Handle**



## PRODUCT DETAILS


- Adjustable wrenches developed according to the scientific ERGO™ process
- Maximum comfort with minimum effort thanks to ergonomic design
- 40% wider opening compared to a standard adjustable wrench
- Extra-wide jaw opening with a shorter handle than a standard wrench offers accessibility to work in confined spaces
- Reversible toothed jaw for working with pipes up to 34 mm
- The jaw does not fall out even at maximum opening of the wrench
- Head combines slim design for accessibility with strength for performance
- Laser scale in mm for pre-adjusting and accurate measurement
- Skydrol- and oil-resistant rubber handle
- Ergonomically designed thermoplastic elastomer handle distributes pressure uniformly in the hand, reducing the risk for work related injuries
- High-performance alloy steel forged in one single piece
- Phosphate finish, precision-hardened and anti-corrosion treated
- Left turning screw
- Standards: ISO 6787, DIN 3117, ASME B107.8 and BS 6333

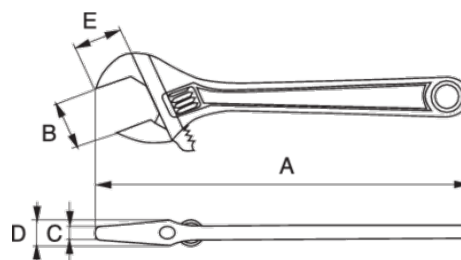

**Follow the Fish!**



PRODUCT ATTRIBUTES

Product	A	A	B	C	D	E	
9031P	218 mm	8 in	39 mm	5 mm	13.4 mm	34 mm	340 g

