

CLB-JL-8160


Cable Mount, Plug Type A 3.0 USB Connector



Product Details

The Farnell CLB-JL-360 cable mount Plug Type A 3.0 USB Connector has an operating temperature range of -20.0°C to +85°C and voltage rating of 30 Volts.

- Gender: Male
- USB Type: A
- Mounting Type: Cable Mount
- Termination Method: Screw terminal
- USB Version: 3.0

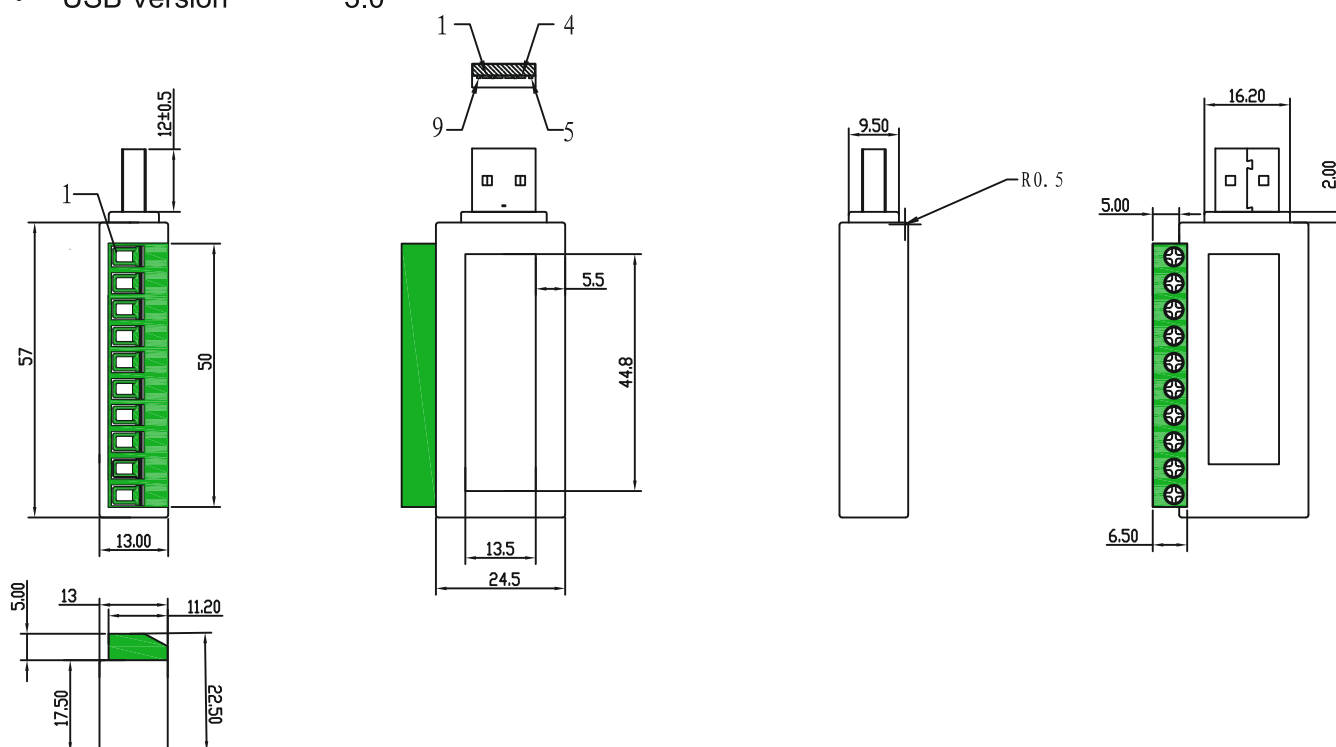

Specifications

Attribute:	Value:
Gender	Male
USB Type	A
Mounting Type	Cable Mount
Termination Method	Screw terminal
USB Version	3.0
Number of Ports	2
Current Rating	1.0A
Voltage Rating	30.0 V
Minimum Operating Temperature	-20.0°C
Maximum Operating Temperature	+85°C

Wire Diagram

P1	P2
1	1 (VBUS)
2	2 (DATA-)
3	3 (DATA+)
4	4 (GND)
5	5 (SSRX-)
6	6 (SSRX+)
7	7 (GND_DRIN)
8	8 (SSTX-)
9	9 (SSTX+)
10	10 (SHELL)