

IR-68


Flexible InfraRed Thermometers with Laser Pointer



Applications

- Plant / General Maintenance
 - HVAC / R
 - Transportation / Automotive
 - Cooling and Reheating
 - Serving areas
 - Food service Equipment
 - Cold storage
-
- 16" Gooseneck detector is easy to measure the hard-to-reach areas
 - Backlighting illuminates display for measurements at night or in areas with low background light levels
 - Overrange indication
 - Auto Data Hold when measure released
 - Auto Power off

Distance (D) to Spot size (S)
D:S=8:1

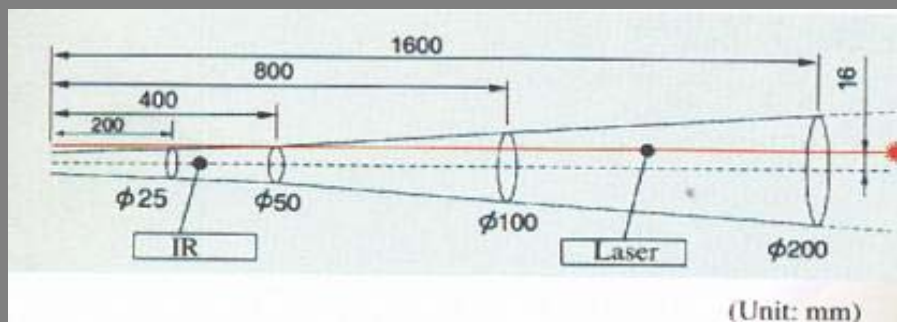

Features

16 inch Gooseneck

User selectable °C or °F

Laser Targeting

Automatic Data Hold

Auto Power Off

White Backlit LCD Display

Overrange indication

Low battery indication

Accessories: 9V battery, Carrying case and Gift box.

Specifications

Range | -50°C to 600°C / -58°F to 1112°F

Response time	Less than 1 second
Resolution	0.1° up to 200°/ 1° over 200°
Basic Accuracy	± 2% of reading or ±2°C/±4°F
Optical resolution	8:1 Distance to spot size
Emissivity	Fixed at 0.95
Size (H x W x D): 163mm x 45mm x 34mm	
Weight: 263g	

