

Check Stock/Pricing by Product No.

Search By Size and Type

[Home](#) / [Products](#) / [NEMA / IP Rated Boxes](#) / [NEMA 1 Hinged Steel Junction Box](#) / Hinged Junction Box with Knockouts JBH-4956-KO

Hinged Junction Box with Knockouts JBH-4956-KO



Model # JBH-4956-KO

[NEMA 1 Hinged Steel Junction Box](#)

- Heavy duty 16-gauge welded steel construction
- Hinged cover with slotted-head quarter-turn cam lock
- Three easily removable concentric knockouts on all four sides for industry standard conduit sizes
- Four wall mounting holes in back
- Embossed grounding hole in bottom allows easy access and flush wall mounting
- Durable ANSI 65 Gray Powder coating
- Complies with NEMA and UL Type 1 rating
- UL listed file E194432

Check Stock / Pricing

Request Modifications

Compare Sizes and Models

External Size L x W x D: 8.00" x 6.00" x 4.00"

Internal Size L x W x D: 7.88" x 5.88" x 3.88"

Weight: 4 lbs

Color: Gray Powder Coat

RoHS Certified: Always Compliant

Latch Style: Slotted-Head Quarter-Turn Cam Lock


Knockouts: Knockouts

NEMA Rating: NEMA 1

Mounting Style: Mounting Holes

Cover Style: Opaque, Hinged Cover

DRAWING

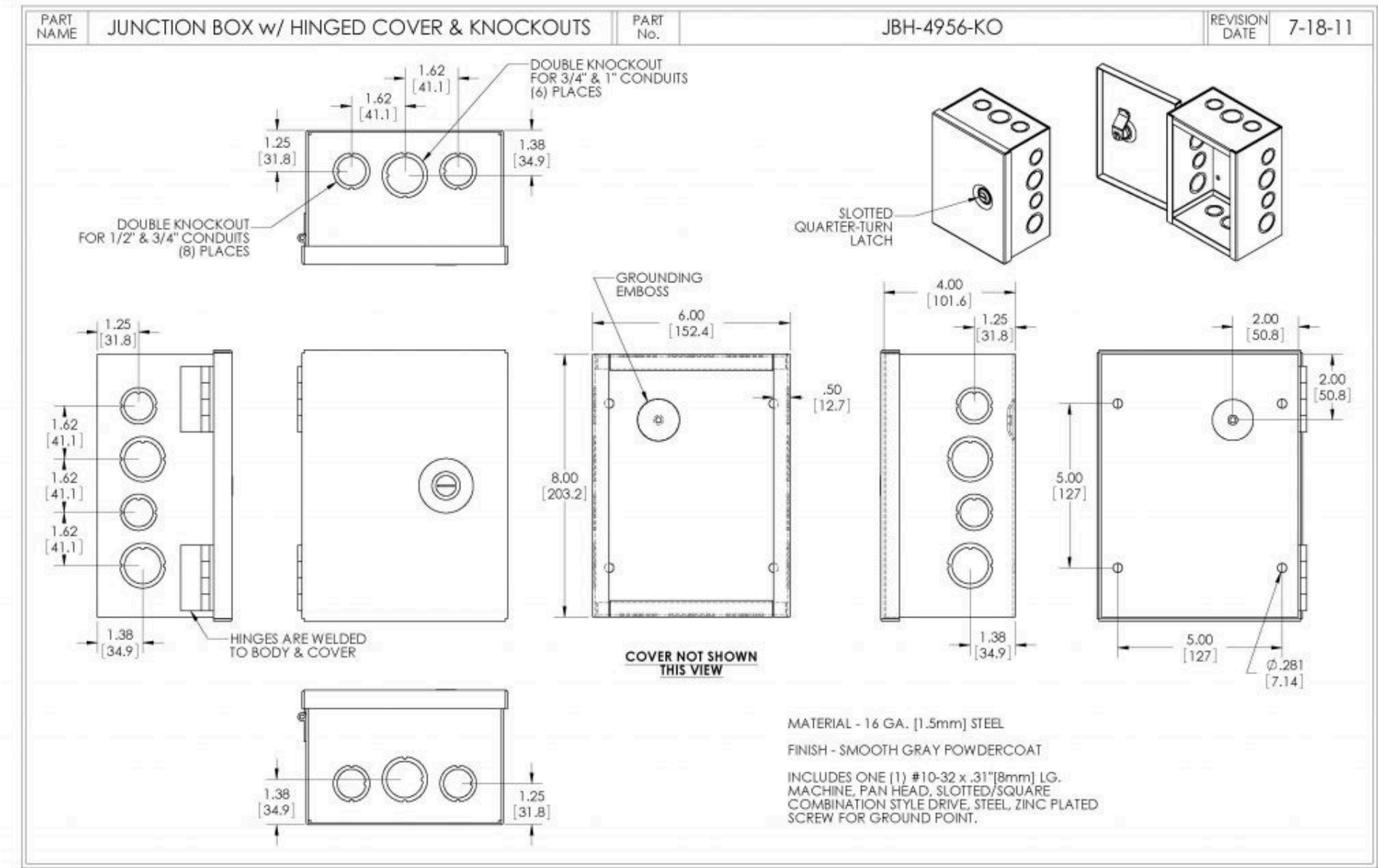

OTHER MODELS IN THIS SERIES

-- External Dimensions --

-- Internal Dimensions --

Model #	External Dimensions	Internal Dimensions
JBH-4944-KO	6.00" x 4.00" x 3.50"	5.88" x 3.88" x 3.38"
JBH-4953-KO	6.00" x 4.00" x 4.00"	5.88" x 3.88" x 3.88"
JBH-4954-KO	6.00" x 6.00" x 3.00"	5.88" x 5.88" x 2.88"
JBH-4945-KO	6.00" x 6.00" x 3.50"	5.88" x 5.88" x 3.38"
JBH-4955-KO	6.00" x 6.00" x 4.00"	5.88" x 5.88" x 3.88"
JBH-4956-KO	8.00" x 6.00" x 4.00"	7.88" x 5.88" x 3.88"
JBH-4957-KO	8.00" x 8.00" x 4.00"	7.88" x 7.88" x 3.88"
JBH-4960-KO	10.00" x 10.00" x 4.00"	9.88" x 9.88" x 3.88"
JBH-4961-KO	10.00" x 10.00" x 6.00"	9.88" x 9.88" x 5.88"
JBH-4958-KO	10.00" x 8.00" x 4.00"	9.88" x 7.88" x 3.88"
JBH-4959-KO	10.00" x 8.00" x 6.00"	9.88" x 7.88" x 5.88"

RELATED PRODUCT SERIES



440-946-3200

Find Distributor/ Rep

Contact Us



[Warranty](#)

[Privacy Policy](#)

[Unsubscribe](#)

©2019 - 2024 BUD Industries, all rights reserved

Contact Us

Name *

First

Last

Company

Email *

Phone *