

## Han® ORV3 Power Bridge, Star Config.

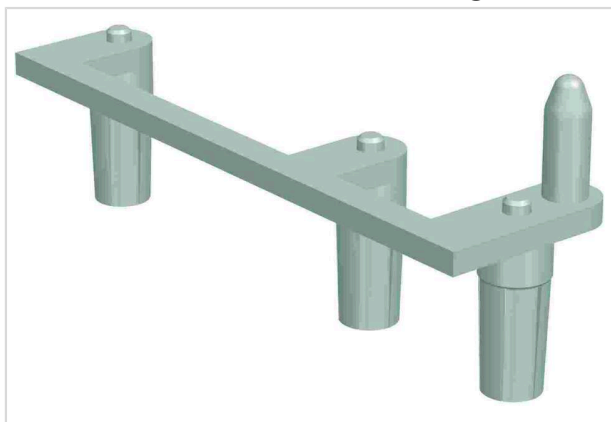


Image is for illustration purposes only. Please refer to product description.

Part number	09 93 000 6250
Specification	Han® ORV3 Power Bridge, Star Config.
HARTING eCatalogue	<a href="https://b2b.harting.com/09930006250">https://b2b.harting.com/09930006250</a>

### Identification

Category	Accessories
Series	Han® ORV3 power
Type of accessory	Contact bridge
Description of the accessory	Configuration #01

### Technical characteristics

Rated current	32 A
Rated voltage	480 V AC 380 V DC
Rated impulse voltage	6 kV
Pollution degree	3
Contact resistance	≤3 mΩ
Limiting temperature	-5 ... +45 °C
Mating cycles	≥100
Degree of protection acc. to IEC 60529	IP20

### Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

## Specifications and approvals

Specifications	OCP V1.0
----------------	----------

## Commercial data

Packaging size	1
Net weight	9 g
Country of origin	USA
European customs tariff number	85366990
GTIN	5713140445147
ETIM	EC002939
eCl@ss	27440392 Connector (accessories)