

PCB Terminal Block


9.52 mm Pin Spacing

- Board Mount PCB
- 30A Current Rating
- Height 21mm
- Modular



MV49xx-9,52-V

Front Wire Entry

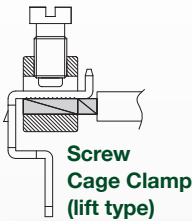

Electrical Ratings

					
Usergroup	B	C	D		
Rated Voltage	300V	-	300V	750V	
Rated Current	30A	-	30A	32A	
Wire Size	<i>solid</i>	30-10 AWG	-	30-10 AWG	0.25mm ² - 6.0mm ²
	<i>stranded</i>	30-10 AWG	-	30-10 AWG	0.25mm ² - 6.0mm ²

Ordering Information

No. Poles	Length (mm)	Std. Pack	Order #
2	19.04	100	MV-492
3	28.56	100	MV-493
4	38.08	100	MV-494
5	47.60	100	MV-495
6	57.12	100	MV-496
7	66.64	100	MV-497
8	76.16	100	MV-498
9	85.68	100	MV-499
10	95.20	100	MV-4910
11	104.72	100	MV-4911
12	114.24	100	MV-4912


Material Specifications

Clamp	Tin-Plated Copper
Solder tab	Tin-Plated Copper
Screw	Galvanized Steel
Insulating Material	Polyamide
Flammability Class	V0 UL94
Operating Temperature	-30°C - +105°C

Installation Data

Screw Size	M3 
Torque	0.8 Nm (7.2 lb.in.)
Stripping Length	max. 9mm
Clamp Opening	3.2 x 3.9mm
PCB Hole Size	1.3mm

Dimensions (mm)

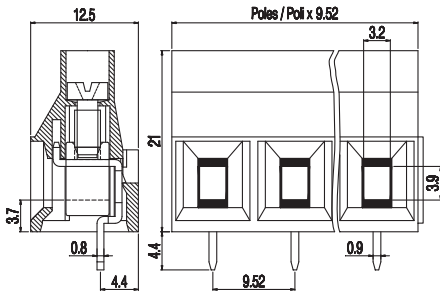

Drilling Diagram

