

Extended Handle Accessories



LK10

DOOR INTERLOCK HANDLES

(padlockable with up to three 1/4" padlocks)

LK10 (Y/R) UL:


- Single hole mounting (22.5mm)

LK11 (Y/R) U:

- Retention mechanism (only rotates 90° from off to on, keeps handle in off position while cabinet door is open)



Example of handle with 1/4" padlocks.

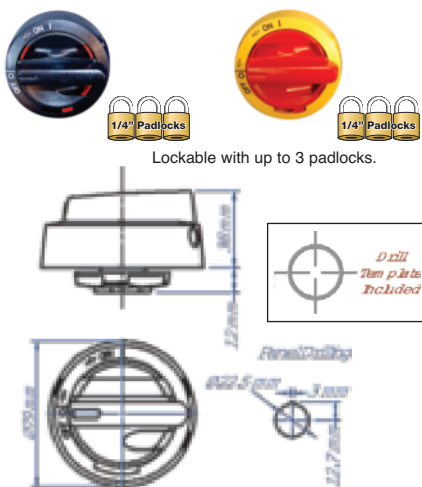



Lockable with up to 3 padlocks.



LK11



 Lockable with up to 3 padlocks.

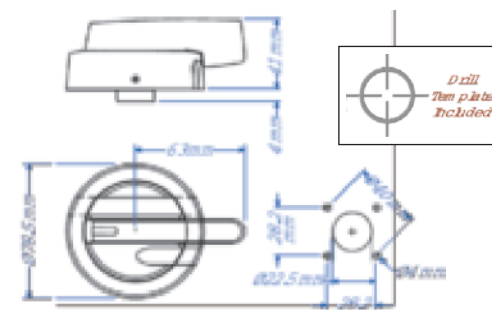


Cat. No.	LK10 UL	LK10 Y/R UL	LK11 U	LK11 Y/R U
Environmental Rating (UL)	UL Type 4X	UL Type 4X	UL Type 4X	UL Type 4X
(IEC)	IP66	IP66	IP67	IP67
Color	Black	Yellow/Red	Black	Yellow/Red

DEFEATABLE MECHANISM -

OPERATING INSTRUCTIONS

The defeater mechanism allows a screwdriver to be inserted to release the lock and open the door with the mechanism in the ON position.

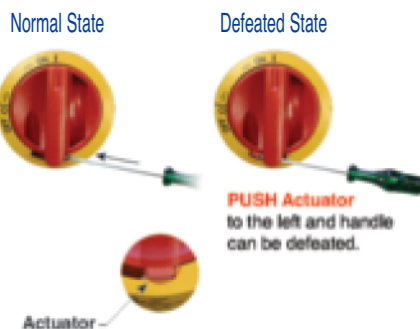

Defeated State

PUSH Actuator to the left and handle can be defeated.

Actuator

Normal State

Defeated State

BREAK TAB by pushing screwdriver or equivalent with some force.

PUSH IN SCREWDRIVER to defeat mechanism



Warning: The defeater mechanism should only be used by a trained professional.

Note: After tab is broken, NEMA Type 4X rating will be lost.


DOOR INTERLOCK SHAFT

The steel shaft ensures reliable operation even in the toughest conditions.



Cat. No.	L100 AD11-ST	L200 AD11-ST	L300AD11-ST
Length (L)	100 mm	200 mm	300 mm
Material	Steel	Steel	Steel

SHAFT LENGTH CUTTING GUIDELINE

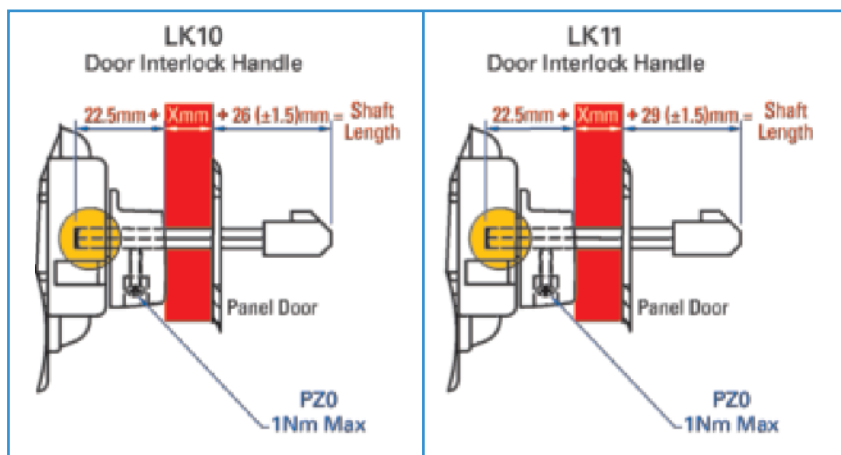

SHAFT CUTTING RECOMMENDATIONS

