


C83C01UXXX

(M8 Cordset, 3 Position, 24 AWG Unshielded PVC, Female Straight to Open End)



FEMALE FACE VIEW

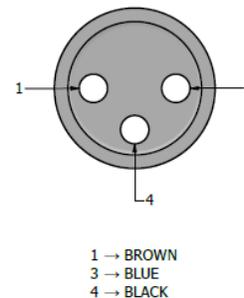

- Mueller's C83C01UXXX is an M8 3-pin single ended, unshielded instrumentation cable with a straight female connector on one end and an open stripped end on the other.
- Keyway – A Coding
- Utilizes a 3-conductor 24 AWG PVC-insulated, black cable.
- Ratings:
 - Current: 3 A
 - Voltage: 60 V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant