




BU-4150061XXX

(Cable Assembly Coaxial SMA Straight to N-type Straight Male to Male RG-142)

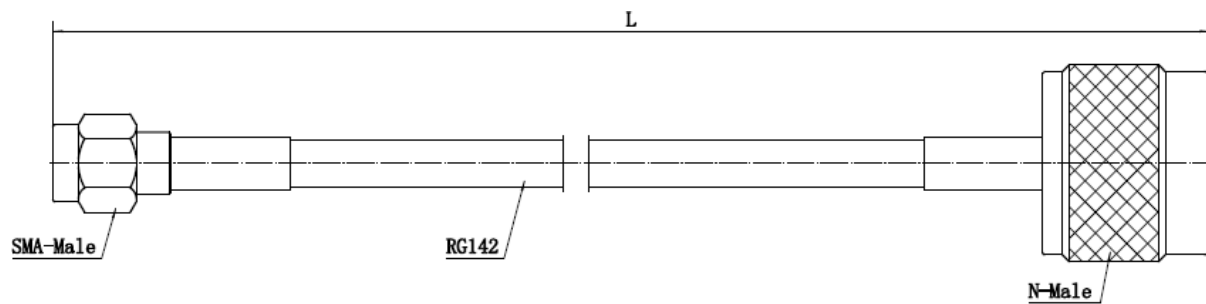

Mueller Electric Company
2850 Gilchrist Rd. Bld 5A
Akron, OH 44305

www.muellerelectric.com

Toll Free: 800.955.2629
Phone: 330.780.2525
Fax: 330.780.2524

Electrical Ratings

Electrical ratings of a cable assembly are determined by the limiting connector type and cable size.

Connector	Cable	Connector Impedance (Ohms)	Frequency (GHz)	VSWR	Working Voltage (At Sea Level)
SMA, N Type	RG-142	50	DC-6	1.2 MAX	335V

Product Attributes

Gender	Male to Male
Style	SMA to N-type
1st Connector	Gold Plated SMA Male Plug Straight
2nd Connector	Nickel Plated N-type Male Plug Straight
Features	Shielded
Operating Temperature	-65°C (-85°F) to 150°C (302°F)
BU-4150061012	12" (304.8 mm)
BU-4150061024	24" (609.6 mm)
BU-4150061036	36" (914.4 mm)
BU-4150061060	60" (1524 mm)
RoHS 3 Compliant	