


### CL5AD08UXXX

(M12 Cordset, 5 Position, 16 AWG Unshielded, Male Straight to Female 90°)




MALE FACE VIEW

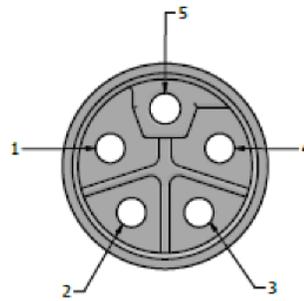

1 → BLUE  
2 → GRAY  
3 → BLACK  
4 → BROWN  
5 → GREEN/YELLOW

FEMALE FACE VIEW

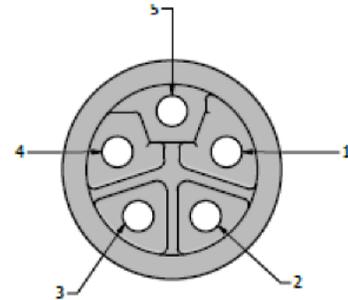

1 → BLUE  
2 → GRAY  
3 → BLACK  
4 → BROWN  
5 → GREEN/YELLOW

- Mueller's CL5AD08UXXX is an M12 L coded 5-pin double ended, unshielded instrumentation cable with a straight male connector on one end and a 90° female connector at the other.
- Keyway – L Coding
- Utilizes a 5-conductor 16 AWG HD-PE-insulated, unshielded cable.
- Ratings:
  - Current: 16 A
  - Voltage: 63V AC/DC
- Material:
  - Coupling Nuts – Nickel Plated Brass
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.  
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant