

# NEBO™ BANDO™ 1K

## LIGHT MODES

- High (1,000 lumens): 5 hours / 35 meters
- Medium (400 lumens): 8 hours / 23 meters
- Low (80 lumens): 28 hours / 10 meters
- Red (18 lumens): 22 hours / 4 meters
- Red Hazard (ON/OFF in 0.5 sec intervals)
- Red Signal (directional chasing pattern)

## DESIGN

- USB-C rechargeable
- Power bank
- Smart Power Control™ (SPC)
- Power Memory Recall
- Direct-to-Red
- 120° rotating light strip
- Durable ABS + PC construction
- Water and impact-resistant (IPX4)
- Powerful magnetic housing

## OPERATION

- Dual, backlit buttons with LED power and battery indicators

## ACCESSORIES


- Adjustable, wearable elastic strap
- Dual buckle system with padded hanging hooks
- USB-A to USB-C charging cable

## BATTERIES


- Powered by 2x 18650 Lithium-Ion rechargeable batteries (included)  
(Recharge time: 4 hours @ 2.0A, 8 hours @ 1.0A, 16 hours @ 0.5A)

## SPECS

- 0.65 lb.
- Adjustable band length: 53" min / 58" max
- Buckle-to-buckle length: 40" min / 45" max

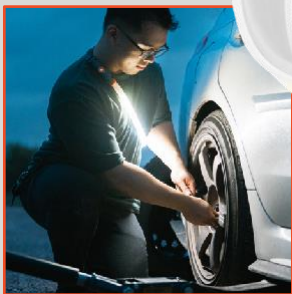

CALIFORNIA REQUIRED ⚠️ WARNING | Cancer and Reproductive Harm | [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

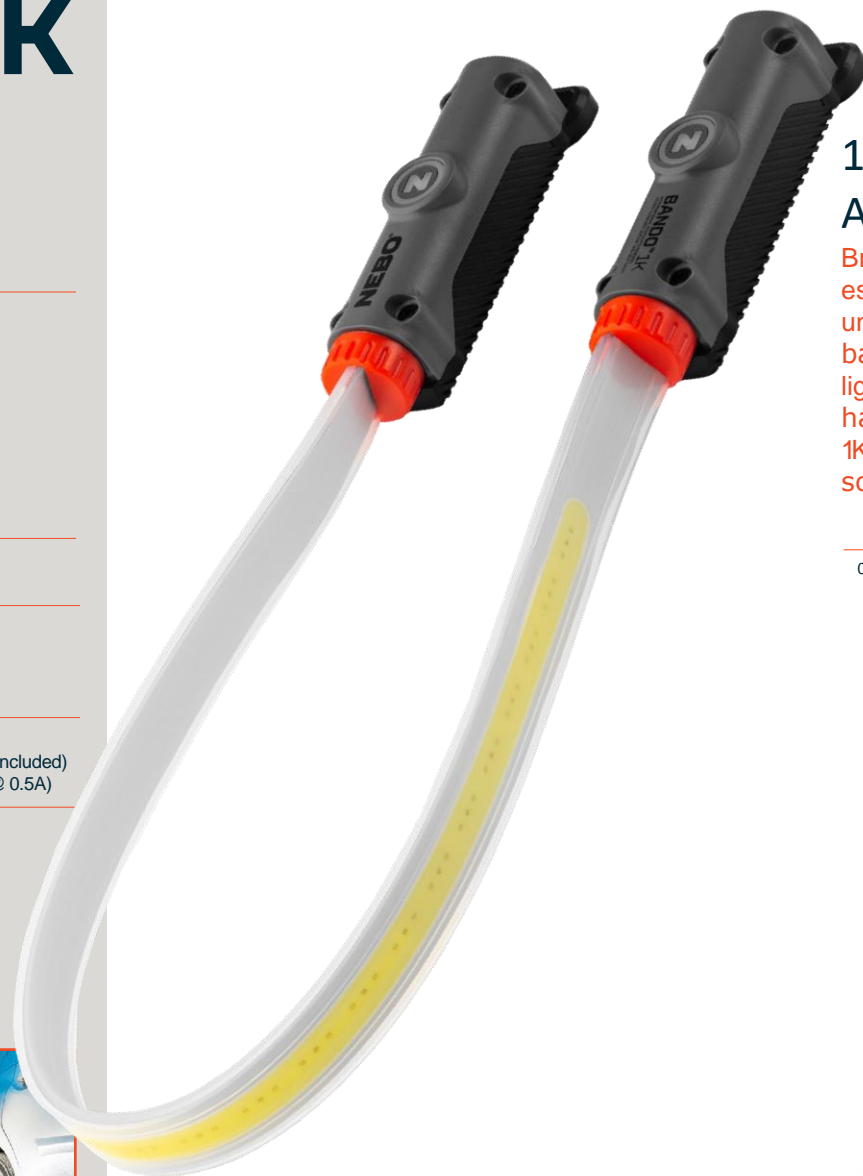

## 1000-LUMEN AUTOMOTIVE WORK LIGHT

Breaking down along the roadside is daunting, especially at night. Be prepared for the unexpected with the BANDO 1K. This flexible light band provides up to 1,000 lumens of bright area lighting. With its powerful magnetic housing, hanging hooks, and wearable strap, the BANDO 1K quickly transforms into three versatile lighting solutions, helping you see, be seen, and stay safe.

UPC CODE

ITEM

044435919865

NEB-WLT-0034

Natural Dimensions  
(H) 14.96" x (W) 8.66" x (D) 1.5"  
PDQ Dimensions  
(H) 2.5" x (W) 9.58" x (D) 10.98"

