


# PXP4002/001/02P Datasheet

Product Name // Pre-wired Flex Cable Connector - Right Angle - 1m - 2 Contacts - Plug

 [View Product Page](#)

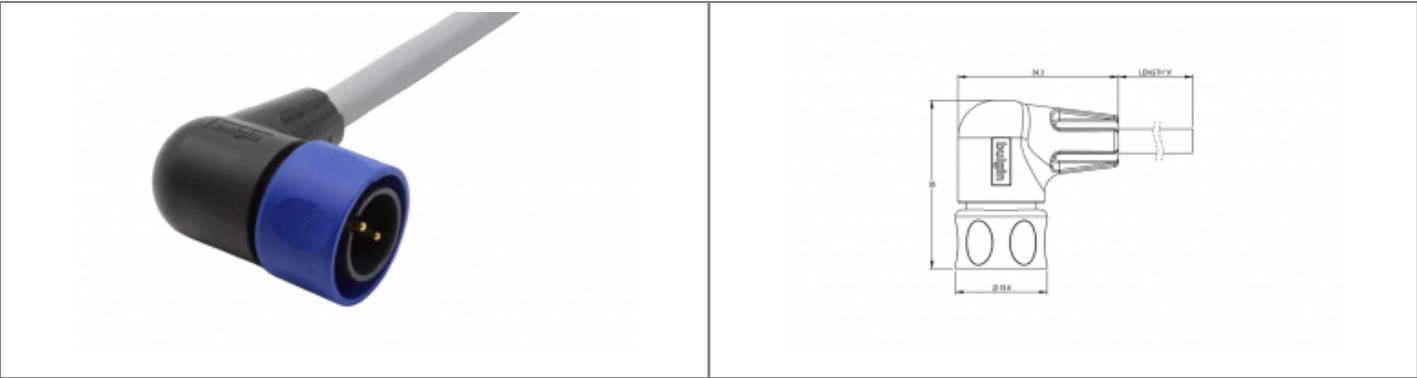

// Product Description:

- Pre-Wired Flex Cable Connector - Right Angle
- Water and dustproof to IP68 when mated with compatible connector
- 4000 Series Buccaneer to blunt cut wire
- 1m Cable Length
- 2 Contacts - Plug
- Sealing Cap available separately to maintain IP rating of unmated connectors
- Mates with front and rear panel mounting connectors - and inline cable connectors

// General Information:

|                                 |                                |
|---------------------------------|--------------------------------|
| Product Display Title:          | Pre-Wired Flex Cable Connector |
| Product Family:                 | Circular Power Connectors      |
| Product Series:                 | 4000 Series Buccaneer          |
| Approvals:                      | cUL, UL, VDE                   |
| Body Colour:                    | Black                          |
| Body Material:                  | Polyamide (PA)                 |
| Body Material Type:             | Plastic Body                   |
| Cable Length:                   | 1m                             |
| Contact Type:                   | Plug Contact                   |
| Coupling Type:                  | Bayonet Lock                   |
| Current Max:                    | 13A                            |
| Diameter Over Coupling Ring Mm: | 19.7mm                         |
| Flamability Rating:             | UL94V-0                        |
| Function:                       | Flex Cable Connector           |
| Ip Rating:                      | IP66, IP67, IP68               |
| Max Operating Temperature:      | +120°C                         |
| Min Operating Temperature:      | -30°C                          |
| Number Of Contacts:             | 2 Contacts                     |
| Rohs Compliant:                 | Yes                            |
| Voltage Max:                    | 600V                           |

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry  
you'd like to talk to us about?



[Click Here To Contact Us](#)