


Features

- Protects equipment users from harm
- Bright Nickel Chrome Plating
- Steel Finger guard
- Fixing centers 71.5mm by 71.5mm

Highland Finger Guard

Part Number: HIG-W80

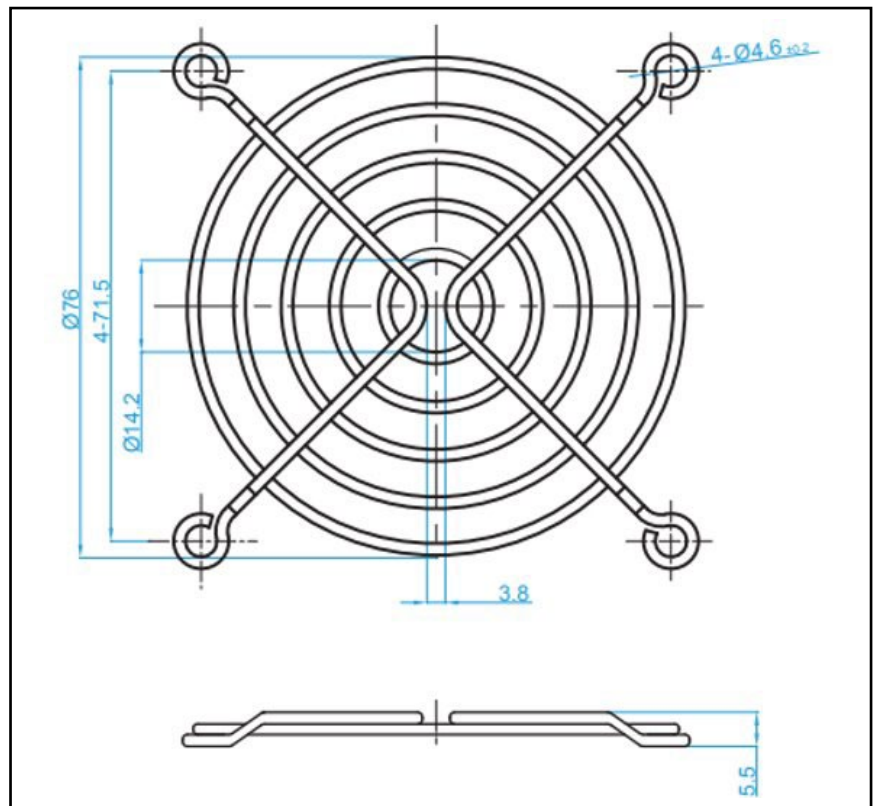

Product Description

- Our 80mm Fan wire finger guard protects the fan from damage and equipment users from harm.
- Made from high-quality C1008 Steel material for exceptional durability and longevity.
- Plated with bright nickel chrome for extra protection against corrosion and wear and tear.
- Ring diameter of 1.8mm and rib diameter of 1.8mm.
- Fixing centres 71.5mm x 71.5mm ± 0.5 mm, ensuring a perfect fit for your 80mm fan.
- RoHS compliant, ensuring safety and free from hazardous materials.
- Various plating styles are available upon request for a perfect finish.

General Specifications

Guard Type	80mm wire guard
Frame Material	C1008 Steel
Frame Finish	Bright nickel chrome
For Use With	80mm axial fans
Weight (g):	21
Tariff Code:	84149000
Guard Type	80mm wire guard

Mechanical Specifications

Fan Size	80mm
Fixing centres	71.5mm x 71.5mm
Length	80mm
Width	80mm
Thickness	5.5mm
Mounting Hole Diameter	4.6mm

Approvals

Compliance/Certifications	RoHS Compliant
---------------------------	----------------