

斯闊企業股份有限公司
普崙電子股份有限公司



S. Square Enterprise Co., Limited
Pro-Wave Electronics Corporation

新北市中和區中山路二段 348 巷 8 號 4 樓 P.O. Box 1-70 Chung Ho, Taiwan, ROC; Tel: (02)-22465101 Fax: Int'l +886-2-22465105

Model Number: 400ER18S

Specification:


Center Frequency	40.0±1.0KHZ
Sensitivity	-67dB @ 0dB=1Volt/ μ bar
Bandwidth	1.5KHZ @ -6dB
Capacitance	2800±20%pF @ 1KHZ
Operation Temperature	-30° to +70°C
Storage Temperature	-40° to +80°C
Allowable Input Power	0.2 Watt

Model Number: 400ET18S

Specification:

Center Frequency	40.0±1.0KHZ
Sound Pressure Level Measured at 30cm, 10Vrms Sine Wave input	112dB @ 0dB re 0.0002 μ bar
Bandwidth	1.5KHZ @ -6dB
Capacitance	2800±20%pF @ 1KHZ
Operation Temperature	-30° to +70°C
Storage Temperature	-40° to +80°C
Allowable Input Power	0.2 Watt

Test Circuit:

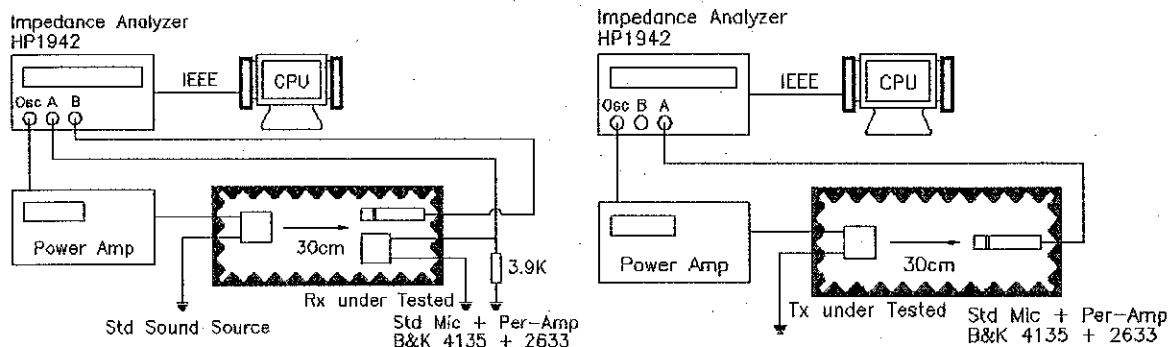

Dimensions: in mm

