



**Mallory Sonalert Products, Inc.**

Part #: **JTC028-RY-CD**

## Sales Outline Drawing

Revision: **A**

### Specifications:


Stack Number:	1	2			
LED Color:	RED	YELLOW			
LED Operation:	Continuous	Continuous			
Connection Wires:	Red and Brown	Yellow and Brown			
LED Current Draw:	<50 mA	<60 mA			
Rated Voltage:	24 VAC/DC				
Operating Voltage:	20-28 VAC/DC				
Total Max Current:	<110mA				
Operating Temperature:	-25° ~ +60°C				
Lens Color:	Transparent - matching LED stack color				
Material:	Lexan CFR7431				
Mounting Method:	Direct Mount using 1/2" NPT Stainless Steel Pipe and Nut				
Weight Typical (g):	210				
NEMA 12:	Approved				
Options:	Please contact factory.				

**Dimensions:** Inches (mm)

**cUL Recognized CE Certified**

**ROHS Compliant**

PATENT NUMBER(S) 10309594 D898600

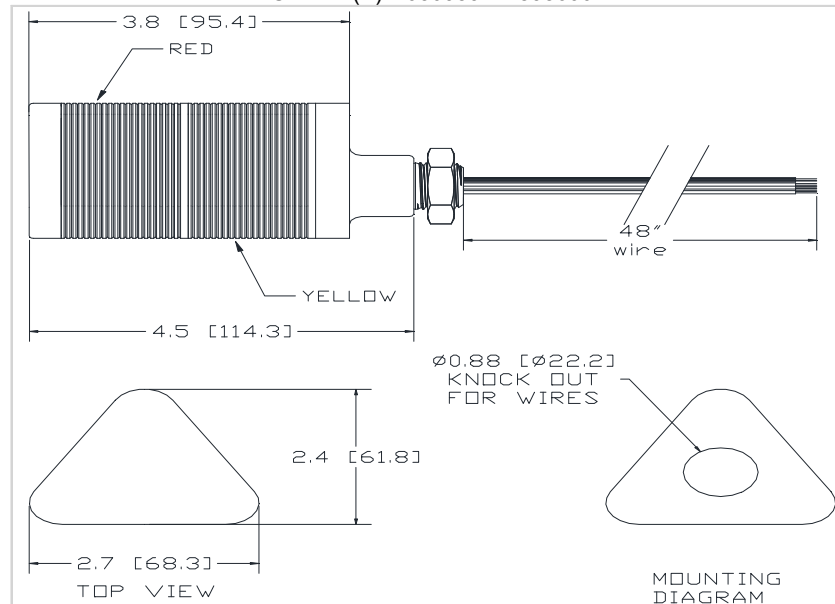

LED OPERATION: CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.