

Sales Outline Drawing

Specifications:

Stack Number:	1	2		
LED Color:	YELLOW	GREEN		
LED Operation:	Continuous	Continuous		
Connection Wires:	Yellow and Brown	Green and Brown		
LED Current Draw:	<230 mA	<190 mA		
Rated Voltage:	120 VAC			
Operating Voltage:	90-120 VAC			
Total Max Current:	<420mA			
Operating Temperature:	-25° ~ +60°C			
Lens Color:	Transparent - matching LED stack color			
Material:	Lexan CFR7431			
Mounting Method:	Direct Mount using 1/2" NPT Stainless Steel Pipe and Nut			
Weight Typical (g):	215			
NEMA 12:	Approved			
Options:	Please contact factory.			


Dimensions:

Inches (mm)

cUL Recognized

ROHS Compliant

PATENT NUMBER(S) 10309594 D898600

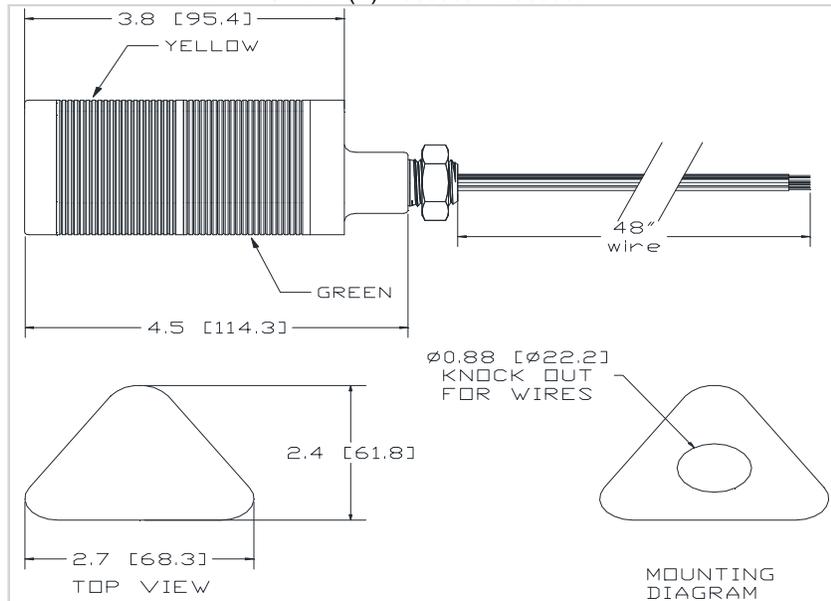

LED OPERATION: CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.