


E/MBK - End bracket



1401637
<https://www.phoenixcontact.com/in/products/1401637>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

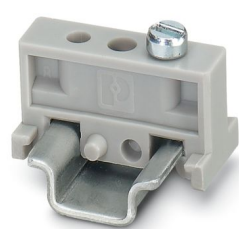

End clamp, width: 6.2 mm, color: gray

Your advantages

- Large-surface marking
- Can be screwed onto NS 15 DIN rails
- Can be mounted directly on the mounting panel as an MBK terminal block

Commercial data

Item number	1401637
Packing unit	100 pc
Minimum order quantity	100 pc
Sales key	BE7
Product key	BE7111
Catalog page	Page 539 (C-3-2019)
GTIN	4017918020484
Weight per piece (including packing)	1.633 g
Weight per piece (excluding packing)	1.62 g
Customs tariff number	39269097
Country of origin	PL

E/MBK - End bracket

1401637

<https://www.phoenixcontact.com/in/products/1401637>



Technical data


Product properties

Product type	End bracket
Data management status	
Article revision	02

Connection data

Tightening torque	0.4 ... 0.5 Nm
-------------------	----------------

Dimensions

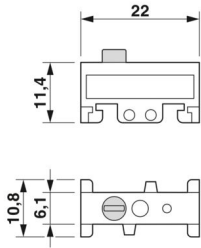Dimensional drawing	
Width	6.2 mm
Height	22 mm
Depth	11.4 mm
Depth on NS 35/7,5	13 mm
Length	22 mm

Material specifications

Color	gray (RAL 7042)
Material	PA
Flammability rating according to UL 94	V2
Coating	3.2 mm fixing hole

Environmental and real-life conditions


Ambient conditions	
Ambient temperature (operation)	-60 °C ... 105 °C (max. short-term operating temperature RTI Elec.)
Ambient temperature (storage/transport)	-25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C)
Ambient temperature (assembly)	-5 °C ... 70 °C
Ambient temperature (actuation)	-5 °C ... 70 °C
Permissible humidity (storage/transport)	30 % ... 70 %

Mounting

Mounting type	NS 15
---------------	-------

Drawings

Dimensional drawing

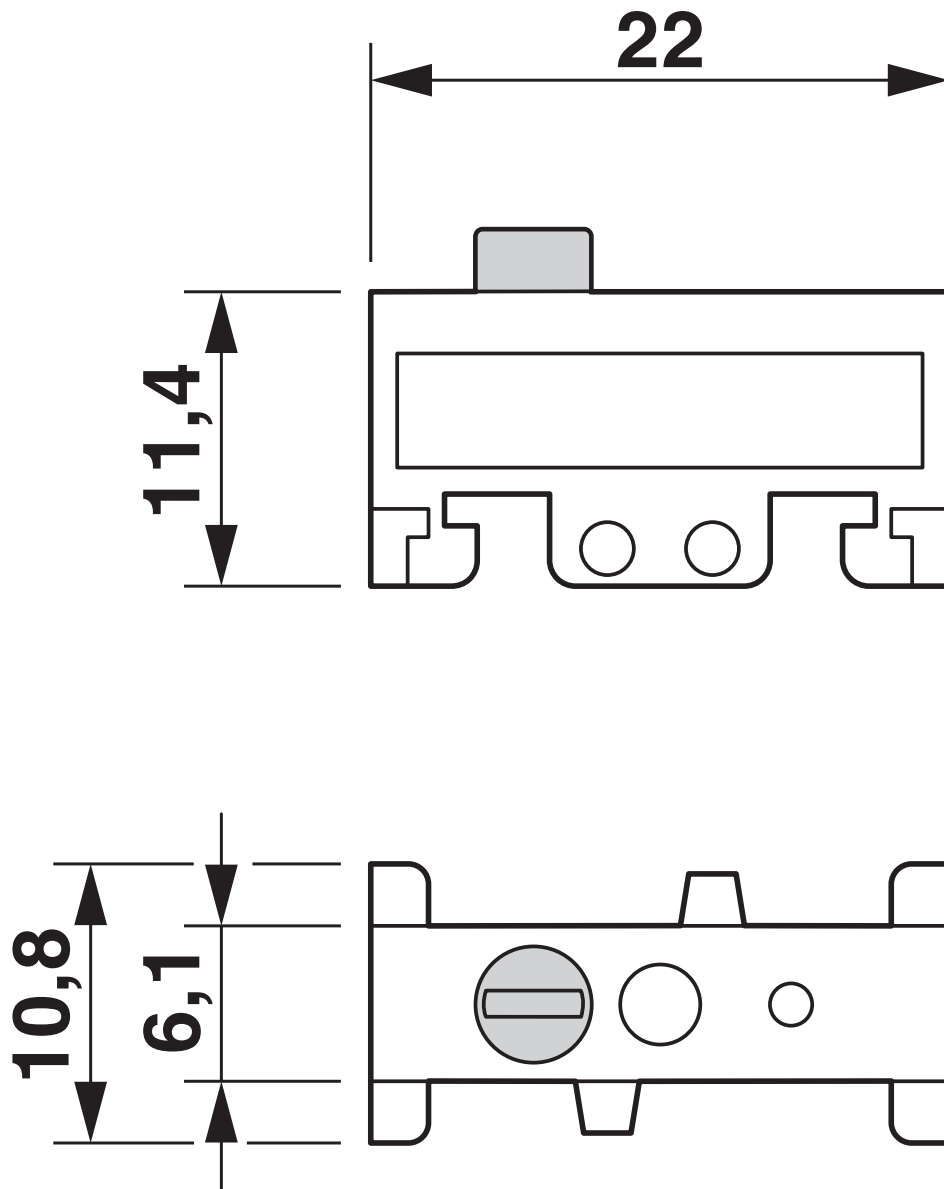

E/MBK - End bracket



1401637

<https://www.phoenixcontact.com/in/products/1401637>

Classifications

ECLASS

ECLASS-11.0	27141135
ECLASS-12.0	27141135
ECLASS-13.0	27250302

ETIM

ETIM 9.0	EC001041
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

E/MBK - End bracket



1401637
<https://www.phoenixcontact.com/in/products/1401637>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in