

CAB P 1008030

FIBOX
Enclosing innovations



Sample image

Order symbol : CAB P 1008030

Product nr : 8104309

Description : Polyester cabinet


Remarks : Grey door

EAN : 6418074050069

El. number :

- Finland : 3424145
- Denmark : 8212018060
- Sweden : 2539829

Including : Cabinet base, door with PUR gasket, 3mm double bit lock(s) with transport and plastic key, screws for mounting plate/DIN-rail and wall fastening lugs with screws. Wall mounting screws not supplied.

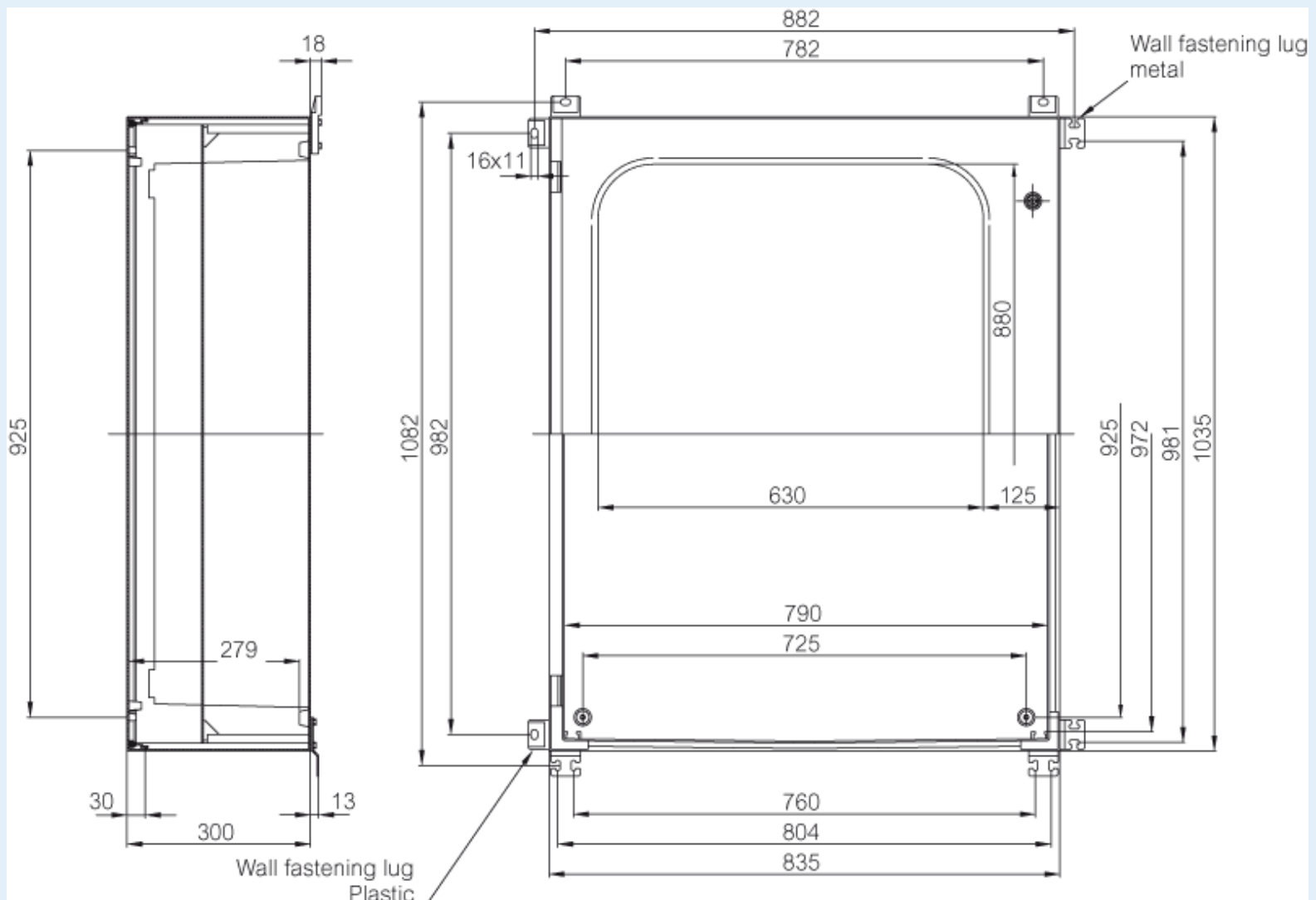

Dimensions :	Height	Width	Depth
mm :	1000	800	300
inch :	39.37	31.5	11.81

Materials :	
Material :	Glass Fiber Reinforced Polyester
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :	
Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Accessories :	
MPX 10080	Mounting Plate, for enclosures: (1000 x 800 x 1)
MB CAB	Swing door kit (187 x 145 x 29)
MPP 10080	Mounting Plate, for enclosures: (1000 x 800 x 2)
MF10080	Mounting Frame with DIN-rails, for enclosures: (1000 x 800 x 1)
FP 10080-D	Swing door/Front plate, for enclosures: (1000 x 800 x 1)
FP 10080-5x36	Front Plate with DIN openings, for enclosures: (1000 x 800 x 1)
MP 10080	Mounting plate, for enclosures: (1000 x 800 x 3)

Ratings :	
Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK10;
electrical_insulation :	Totally insulated
UV resistance :	UL 746C
Flammability Rating :	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C :	960C