



SP Structure+™ Family

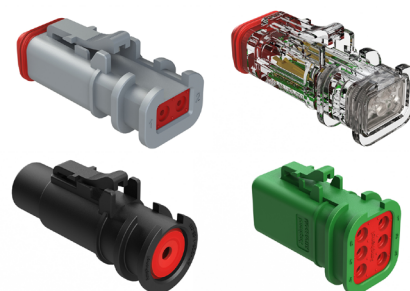
Overmold Compatible Connectors

StructurePlus™ AT: 2, 3, 4, 6, 8, and 12 position

StructurePlus™ AT LED: 2 position

StructurePlus™ ATP: 2, 4 and 6 position

StructurePlus™ ATHD: Single position



Amphenol Sine Systems' **StructurePlus™ Family** of overmold compatible connectors are an **engineered, one-piece, solid body construction and are specifically designed for cable assembly operations requiring custom molding or shrink tube requirements**. The added connector structure results in enhanced connection integrity that is an essential component for connecting cable in harsh environments. IP ratings vary depending on series. The **StructurePlus™** feature retains their respective performance characteristics for each product series.

Key Features

- Engineered one-piece solid body construction, eliminates previously required snap-on-back shell
- Front and Rear Seals (Standard or Reduced Diameter Rear Seals Available)
- Intermatable with industry standard connectors



Potential Applications: Heavy Duty, Transportation, Marine, Diagnostic, Military, Alternative Energy, Agricultural as well as other demanding interconnect applications.

Technical Specifications

Operating Temperature	-55°C to +125°C
Max Current	13A (StructurePlus™ AT/LED) 25A (StructurePlus™ ATP) 25-60A (StructurePlus™ ATHD)
Housing/Wedge Body	Thermoplastic
Seals	Silicone Elastomer
Wire Range (AWG)	14-20AWG (StructurePlus™ AT/LED) 10-14AWG (StructurePlus™ ATP) 6AWG (StructurePlus™ ATHD)
Contacts	Copper Alloy, Nickel-Plated
IP Rating	IP67 mated (StructurePlus™ AT/LED) IP68 1M of water for 24 hours (StructurePlus™ ATP) IP69K mated (StructurePlus™ ATHD)
Vibration	Continued continuity without degradation to mechanical or physical attributes following vibration. (max acceleration 20 g's at Sine sweep of 10-2000Hz)

Dielectric Value	Less than 2 milliamps current leakage at 1500V AC
Corrosion Resistance	No evidence of corrosion after 48 hours of salt spray per MIL-STD1344, method 1001.
Fluid Resistance	Connectors show no damage when exposed to most fluids used in industrial application.
Insulation Resistance	1000 megohms minimum 25°C
Thermal Cycle	No cracking, chipping or leaking after 20 test cycles from -55°C to +125°C.
Physical Shock	No unlocking, unmating or other unsatisfactory results during or after 50 G's in each of three usually perpendicular planes. No electrical discontinuities longer than 1 microsecond. MIL-STD 202. Method 213, Condition "C".
Vibration	Maintains continuity and exhibits no mechanical or physical damage after vibration levels of 20 G's at 10-2000 Hz.
Mating Cycles	>100

A Series™ Family



Standard products. Custom solutions
Customer Service +1 800 394 7732



StructurePlus™ AT - Plugs (See individual datasheets on www.amphenol-sine.com for full specs, faceviews, keying location and product dimensions.)

 
Image	Part Number	Description	Size	Amp
	AT06-2S-OMBLK	2 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMRDBLK	2 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMBLU	2 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Blue Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMRDBLU	2 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Blue Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMBRN	2 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMRDBRN	2 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMGRN	2 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMRDGRN	2 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMGRY	2 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMRDGRY	2 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMRED	2 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Red Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMRDRED	2 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Red Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMWHT	2 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), White Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMRDWHT	2 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), White Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AT06-2S-OMYEL	2 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Yellow Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13

Image	Part Number	Description	Size	Amp
	AT06-2S-OMRDYEL	2 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Yellow Body (Requires Wedgelock AW2S. Keyed Options Available.)	16	13
	AW2S	2 Position, Plug Wedgelock, AT Series™, Green Body	-	-
	AW2S-A	2 Position, Plug Wedgelock, AT Series™, Keyed A, Grey Body	-	-
	AW2S-B	2 Position, Plug Wedgelock, AT Series™, Keyed B, Black Body	-	-
	AW2S-C	2 Position, Plug Wedgelock, AT Series™, Keyed C, Green Body	-	-
	AW2S-D	2 Position, Plug Wedgelock, AT Series™, Keyed D, Brown Body	-	-
	AT06-3S-OMBLK	3 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMRDBLK	3 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMBLU	3 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Blue Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMRDBLU	3 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Blue Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMBRN	3 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMRDBRN	3 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMGRN	3 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMRDGRN	3 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMGRY	3 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMRDGRY	3 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMRED	3 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Red Body (Requires Wedgelock AW3S.)	16	13

Image	Part Number	Description	Size	Amp
	AT06-3S-OMRDRED	3 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Red Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMWHT	3 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), White Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMRDWHT	3 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), White Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMYEL	3 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Yellow Body (Requires Wedgelock AW3S.)	16	13
	AT06-3S-OMRDYEL	3 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Yellow Body (Requires Wedgelock AW3S.)	16	13
	AW3S	3 Position, Plug Wedgelock, AT Series™, Green Body	-	-
	AT06-4S-OMBLK	4 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMRDBLK	4 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMBLU	4 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Blue Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMRDBLU	4 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Blue Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMBRN	4 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMRDBRN	4 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMGRN	4 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMRDGRN	4 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMGRY	4 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13

 
 
Image	Part Number	Description	Size	Amp
	AT06-4S-OMRDWHT	4 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMRED	4 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Red Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMRDRED	4 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Red Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMWHT	4 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), White Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMRDWHT	4 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), White Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMYEL	4 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Yellow Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AT06-4S-OMRDYEL	4 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Yellow Body (Requires Wedgelock AW4S. Keyed Options Available.)	16	13
	AW4S	4 Position, Plug Wedgelock, AT Series™, Green Body	-	-
	AW4S-A	4 Position, Plug Wedgelock, AT Series™, Keyed A, Grey Body	-	-
	AW4S-B	4 Position, Plug Wedgelock, AT Series™, Keyed B, Black Body	-	-
	AW4S-C	4 Position, Plug Wedgelock, AT Series™, Keyed C, Green Body	-	-
	AW4S-D	4 Position, Plug Wedgelock, AT Series™, Keyed D, Brown Body	-	-
	AT06-6S-OMBLK	6 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRDBLK	6 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMBLU	6 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Blue Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRDBLU	6 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Blue Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13

 
 
 
 
 
 
 
Image	Part Number	Description	Size	Amp
	AT06-6S-OMBRN	6 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRDBRN	6 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMGRN	6 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRDGRN	6 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMGRY	6 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRDGRY	6 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRED	6 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Red Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRDRED	6 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Red Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMWHT	6 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), White Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRDWHT	6 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), White Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMYEL	6 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Yellow Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AT06-6S-OMRDYEL	6 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Yellow Body (Requires Wedgelock AW6S. Keyed Options Available.)	16	13
	AW6S	6 Position, Plug Wedgelock, AT Series™, Green Body	-	-
	AW6S-2BLU	6 Position, Plug Wedgelock, AT Series™, Keyed 2, Blue Body	-	-
	AT06-08SA-OMGRY	8 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AW8S.)	16	13
	AT06-08SA-OMRDGRY	8 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AW8S.)	16	13

Image	Part Number	Description	Size	Amp
	AT06-08SB-OMBLK	8 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AW8S.)	16	13
	AT06-08SB-OMRDBLK	8 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AW8S.)	16	13
	AT06-08SC-OMGRN	8 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AW8S.)	16	13
	AT06-08SC-OMRDGRN	8 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AW8S.)	16	13
	AT06-08SD-OMBRN	8 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AW8S.)	16	13
	AT06-08SD-OMRDBRN	8 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AW8S.)	16	13
	AW8S	8 Position, Plug Wedgelock, AT Series™, Green Body	-	-
	AT06-12SA-OMGRY	12 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AW12S.)	16	13
	AT06-12SA-OMRDGRY	12 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AW12S.)	16	13
	AT06-12SB-OMBLK	12 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AW12S.)	16	13
	AT06-12SB-OMRDBLK	12 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AW12S.)	16	13
	AT06-12SC-OMGRN	12 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AW12S.)	16	13
	AT06-12SC-OMRDGRN	12 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AW12S.)	16	13
	AT06-12SD-OMBRN	12 Position, Plug, Socket, StructurePlus™ AT, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AW12S.)	16	13
	AT06-12SD-OMRDBRN	12 Position, Plug, Socket, StructurePlus™ AT, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AW12S.)	16	13

Image	Part Number	Description	Size	Amp
	AW12S	12 Position, Plug Wedgelock, AT Series™, Green Body	-	-

StructurePlus™ AT LED - Plugs (See individual datasheets on www.amphenol-sine.com for full specs, faceviews, keying location and product dimensions.)

	AT06-2S-LED1224V-OMC	2 Position, Plug, Socket, Structure Plus™ AT LED, 12V or 24V, RVP Circuit, Standard Diameter Rear Seal (Red), Green LED, Clear Body (Requires Wedgelock AW2S-LED)	16	13A
	AT06-2S-LED1224VR-OMC	2 Position, Plug, Socket, Structure Plus™ AT LED, 12V or 24V, RVP Circuit, Reduced Diameter Rear Seal (Green), Green LED, Clear Body (Requires Wedgelock AW2S-LED)	16	13A
	AT06-2S-LED12V01-OMC	2 Position, Plug, Socket, Structure Plus™ AT LED, 12V, RVP Circuit, Standard Diameter Rear Seal (Red), Green LED, Clear Body (Requires Wedgelock AW2S-LED)	16	13A
	AT06-2S-LED12VR1-OMC	2 Position, Plug, Socket, Structure Plus™ AT LED, 12V, RVP Circuit, Reduced Diameter Rear Seal (Green), Green LED, Clear Body (Requires Wedgelock AW2S-LED)	16	13A
	AT06-2S-LED24V01-OMC	2 Position, Plug, Socket, Structure Plus™ AT LED, 24V, RVP Circuit, Standard Diameter Rear Seal (Red), Green LED, Clear Body (Requires Wedgelock AW2S-LED)	16	13A
	AT06-2S-LED24VR1-OMC	2 Position, Plug, Socket, Structure Plus™ AT LED, 24V, RVP Circuit, Reduced Diameter Rear Seal (Green), Green LED, Clear Body, (Requires Wedgelock AW2S-LED)	16	13A
	AW2S-LED	2 Position, Plug Wedgelock, AT Series™ LED, Black Body	-	-

StructurePlus™ ATHD - Plugs (See individual datasheets on www.amphenol-sine.com for full specs, faceviews, keying location and product dimensions.)

	ATHD06-1-8S-OM	1 Position, Plug, Socket, StructurePlus™ ATHD, Black Body	8	60
	ATHD06-1-12S-OM	1 Position, Plug, Socket, StructurePlus™ ATHD, Black Body	12	25

StructurePlus™ ATP - Plugs (See individual datasheets on www.amphenol-sine.com for full specs, faceviews, keying location and product dimensions.)

	ATP06-2S-OMGRY	2 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMBLK	2 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMBLU	2 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Blue Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMBRN	2 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25

Image	Part Number	Description	Size	Amp
	ATP06-2S-OMGRN	2 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRED	2 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Red Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMWHT	2 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), White Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMYEL	2 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Yellow Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRDGRY	2 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRDBLK	2 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRDBLU	2 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Blue Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRDBRN	2 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRDGRN	2 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRDRED	2 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Red Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRDWHT	2 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), White Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	ATP06-2S-OMRDYEL	2 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Yellow Body (Requires Wedgelock AWP-2S. Keyed Options Available.)	12	25
	AWP-2S	2 Position, Plug Wedgelock, ATP Series™, Orange Body	-	-
	AWP-2SA	2 Position, Plug Wedgelock, ATP Series™, Keyed A, Grey Body	-	-
	AWP-2SB	2 Position, Plug Wedgelock, ATP Series™, Keyed B, Black Body	-	-
	AWP-2SC	2 Position, Plug Wedgelock, ATP Series™, Keyed C, Green Body	-	-

Image	Part Number	Description	Size	Amp
	AWP-2SD	2 Position, Plug Wedgelock, ATP Series™, Keyed D, Brown body	-	-
	ATP06-4S-OMGRY	4 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMBLK	4 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMBLU	4 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Blue Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMBRN	4 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMGRN	4 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMRED	4 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Red Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMWHT	4 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), White Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMYEL	4 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Yellow Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMRDGRY	4 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMRDBLK	4 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMRDBLU	4 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Blue Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMRDBRN	4 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMRDGRN	4 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMRDRED	4 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Red Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25

 
Image	Part Number	Description	Size	Amp
	ATP06-4S-OMRDWHT	4 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), White Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	ATP06-4S-OMRDYEL	4 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Yellow Body (Requires Wedgelock AWP-4S. Keyed Options Available.)	12	25
	AWP-4S	2 Position, Plug Wedgelock, ATP Series™, Orange Body	-	-
	AWP-4SA	4 Position, Plug Wedgelock, ATP Series™, Keyed A, Grey Body	-	-
	AWP-4SB	4 Position, Plug Wedgelock, ATP Series™, Keyed B, Black Body	-	-
	AWP-4SC	4 Position, Plug Wedgelock, ATP Series™, Keyed C, Green Body	-	-
	AWP-4SD	4 Position, Plug Wedgelock, ATP Series™, Keyed D, Brown body	-	-
	ATP06-6S-OMBLK	6 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Black Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMRDBLK	6 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Black Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMBLU	6 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Blue Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMRDBLU	6 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Blue Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMBRN	6 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Brown Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMRDBRN	6 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Brown Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMGRN	6 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Green Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMRDGRN	6 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Green Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMGRY	6 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Grey Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25

Image	Part Number	Description	Size	Amp
	ATP06-6S-OMRDGRY	6 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Grey Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMRED	6 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Red Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMRDRED	6 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Red Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMWHT	6 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), White Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMRDWHT	6 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), White Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMYEL	6 Position, Plug, Socket, StructurePlus™ ATP, Standard Diameter Rear Seal (Red), Yellow Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	ATP06-6S-OMRDYEL	6 Position, Plug, Socket, StructurePlus™ ATP, Reduced Diameter Rear Seal (Green), Yellow Body (Requires Wedgelock AWP-6S. Keyed Options Available.)	12	25
	AWP-6S	6 Position, Plug Wedgelock, ATP Series™, Orange Body	-	-
	AWP-6SA	6 Position, Plug Wedgelock, ATP Series™, Keyed A, Grey Body	-	-
	AWP-6SB	6 Position, Plug Wedgelock, ATP Series™, Keyed B, Black Body	-	-