



HB-BL

- mounting flange
- blind plug

Data

Ordering data

Product type description	HB-BL
Article number (order number)	103038908
EAN (European Article Number)	4030661617169
eCl@ss number, version 12.0	27-37-12-39
eCl@ss number, version 11.0	27-37-12-39
eCl@ss number, version 9.0	27-37-12-39
ETIM number, version 7.0	EC002023
ETIM number, version 6.0	EC002023

General data

Standards	EN IEC 60947-5-1 EN IEC 60947-1 DIN EN 1672-2
Versions	Front plate mounting
Design	Round
Sealing type	Membrane Lip gaskets
Material of the operators	Stainless steel
Material of the front ring	stainless steel
Colour of the operating element	silver
Colour of the front ring	Silver

Colour of the bellows	Blue
Gross weight	77 g

Mechanical data

Mounting	Screws
Tightening torque of the screw, maximum	1.8 Nm

Mechanical data - Dimensions


Mounting height	7 mm
Note (Mounting height)	Height in front of the front panel.
Mounting depth	4 mm
diameters for the actuating heads	45 mm
Mounting diameter	22.3 mm
Thickness, of the front panel, minimum	1.5 mm
Thickness of the front panel, maximum	6 mm
Spacing	65 x 65 mm

Ambient conditions

Degree of protection	IP67 IP69K
Ambient temperature	-25 ... +80 °C

Pictures

Product picture (catalogue individual photo)

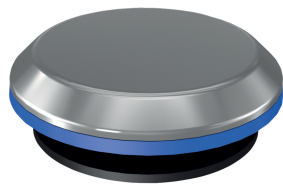

ID: khbb1f01
| 144.5 kB | .jpg | 352.778 x 242.358 mm - 1000 x 687 px - 72 dpi
| 19.5 kB | .png | 74.083 x 50.8 mm - 210 x 144 px - 72 dpi
| 30.5 kB | .jpg | 123.472 x 84.667 mm - 350 x 240 px - 72 dpi