

CLP001-20ST

- Snap-on mounting
- single elements
- single packaging or bulk packaging

Data

Ordering data

Product type description	CLP001-20ST
Article number (order number)	103045541
EAN (European Article Number)	4030661565194
eCl@ss number, version 12.0	27-37-13-02
eCl@ss number, version 11.0	27-37-13-02
eCl@ss number, version 9.0	27-37-13-02
ETIM number, version 7.0	EC000041
ETIM number, version 6.0	EC000041

General data

Versions	Luminaire element
Design	Snap-on
Housing material	Plastic
Gross weight	180,320 g

General data - Features

Probing possible	Yes
------------------	-----

Mechanical data

Mounting	Contact carrier
----------	-----------------

Mechanical data - Connection technique

Termination	Screw terminals
Cable section, minimum	0.5 mm ² , rigid 0.5 mm ² , flexible
Cable section, maximum	2.5 mm ² , rigid 1.5 mm ² , flexible
Note	All indications including the conductor ferrules.
Tightening torque of Clips	1 Nm

Mechanical data - Dimensions

Length	44 mm
Width	9 mm
Height	31 mm

Ambient conditions

Degree of protection of clips or terminals	IP20
--	------

Electrical data

Rated operating voltage	250 VAC
-------------------------	---------

Other data

Note (applications)	Compatible with SMF contact carrier Lamp socket, Product line CLP, Type series CLP, Front mounting switch
---------------------	--


Scope of delivery

Note (scope of delivery, number and type)

Illuminants not included

Pictures

Product picture (catalogue individual photo)

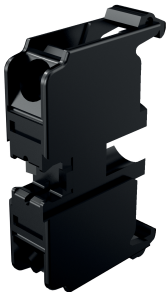

ID: kclp-f03
| 405.0 kB | .jpg | 352.425 x 566.208 mm - 999 x 1605 px - 72 dpi
| 46.2 kB | .png | 74.083 x 118.886 mm - 210 x 337 px - 72 dpi
| 28.8 kB | .jpg | 76.906 x 123.472 mm - 218 x 350 px - 72 dpi

Schmersal India Pvt. Ltd., Plot No - G-7/1, Ranjangaon MIDC, Tal. - Shirur, Dist.- Pune 412 220
The details and data referred to have been carefully checked. Images may diverge from original. Further technical data can be found in the manual. Technical amendments and errors possible.
Generated on: 11/11/2024, 5:23 am