




Part Number : [1061141400](#)

Product Description : EMI MPO Adapter, Simplex, Metal Body, Flange Mount with M2 Holes Style, Shutter, Silicone Gasket

Series Number : 106114

Status : Active

Product Category : Fiber Optic Adapters

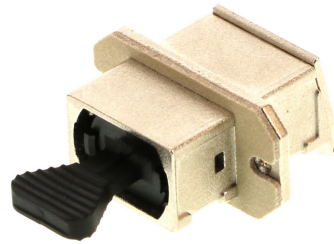


Documents & Resources

Drawings

[1061141400_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2020)9139-DC (19 Jan 2021)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Fiber Optic Adapters
Series	106114
Description	EMI MPO Adapter, Simplex, Metal Body, Flange Mount with M2 Holes Style, Shutter, Silicone Gasket
Component Type	EMI Shielding
Product Family	Optical EMI Shielding Adapters
Product Name	MPO
Type	Adapter
UPC	884982151437

Electrical

Shield Type	EMI Gasket
Shielded	Yes

Physical

Alignment Sleeve	N/A
Angled Physical Contact (APC)	N/A
Color - Resin	N/A
Gender	Female-Female
Material - Housing	Die-Cast
Mounting Style	Flange
Net Weight	10.946/g
Orientation	Straight
Panel Mount	With Flange
Ports	1
Shutter	One Side

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----
