



Careers

Home : Connectors : BNC : TC-240-BM-RA-D

TC-240-BM-RA-D

Type BNC, male (plug), right angle, TC style connector for FBT-240, LMR-240, and TCOM-240 type cables.



Stock Code: 3190-6552

BNC-male (plug)

Inventory Status

Distributor

Qty

Order

DigiKey

28

Buy

Showing 1 to 1 of 1 entries

< 1 >



Specs



Compatible with



Hardware



CAD Model



Documentation



Ask an Expert

Specifications

TC-240- Part Number BM-RA-D		Max Frequency (GHz) 6	Pin Finish Gold
Stock Code 3190-6552		VSWR Freq <1.35:1	Length (mm) 29.7
Interface BNC	VSWR Frequency (GHz) 6	Length (in) 1.17	
Gender Male (plug)	Coupling Nut Knurl	Width (mm) 28.4	
Orientation Right Angle	Inner Contact Attach Solder	Width (in) 1.12	
PIM Rating	Outer Contact Attach Crimp	Weight (g) 25.09	
Impedance (ohms) 50	Body Finish Alballoy	Weight (lb) 0.06	

Compatible with

FBT-240

[LMR-240](#)

[LMR-240-DB](#)

[LMR-240-FR](#)

[LMR-240-LLPX](#)

[LMR-240-MA](#)

[LMR-240-PVC](#)


[TCOM-240](#)

[TCOM-240-FR](#)

Tools and Accessories



CST-240A

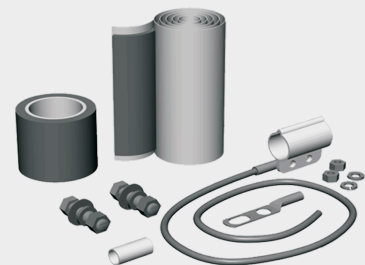

Grounding Kits