



All TIMER, RECEPTACLE AND TAB (278)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts



TE Part # 4-1579007-3
EXTRACTION TOOL KIT



TE Part # 1-1579007-6
EXTRACTION TOOL

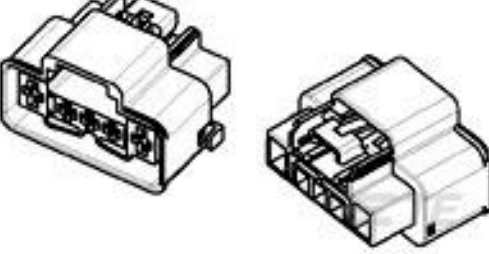

TE Part # 1599317-1
HSG ASSY 5P REC JPT/SPT HYBRID



TE Part # 2151176-1
OCEAN_2.0_APPLICATOR-S-080F110OV-RSM



TE Part # 2151176-2
OCEAN_2.0_APPLICATOR-S-080F110OV-RSA




TE Part # 2305570-1
Strip Terminal Cutter-Side Feed-No Crimp




TE Part # 2836290-1
OCEAN_2.0_APPLICATOR-S-081F110OV-RSM



TE Part # 2836290-2
OCEAN_2.0_APPLICATOR-S-081F110OV-RSA

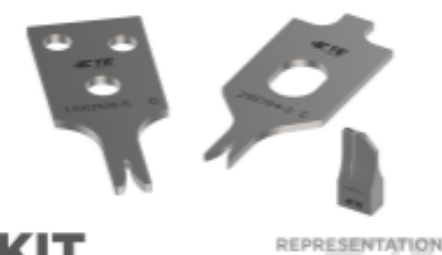

KIT
TE Part # 7-2151176-7
OCEAN_2.0_SPARE_PART_KIT-080F110OV

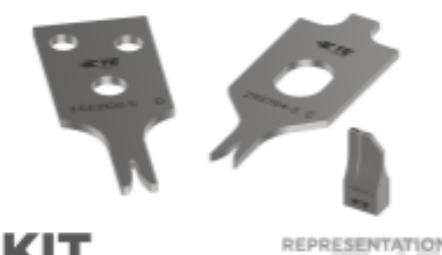

KIT
TE Part # 7-2836290-7
OCEAN_2.0_SPARE_PART_KIT-081F110OV

Also in the Series | [Standard Power Timer](#)



Automotive Housings(32)



Automotive Terminals(49)



Insertion & Extraction Tools(1)


Customers Also Bought



TE Part #62181-1
187 FASTON REC 24-20 AWG TPBR



TE Part #640253-2
RING TONGUE .190 16-12 AWG TPBR

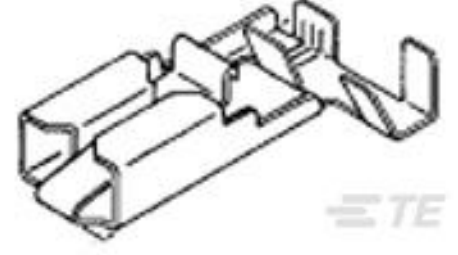

TE Part #926790-6
PL 250 REC TERMINAL-FLAG 17-13 TPBR




TE Part #3-1534796-3
AMP DUOPLUG MK2 CONNECTOR 3P



TE Part #5-2232266-3
PTL 2X3 PLUG HSG GLW WIRE KEY A DGR



TE Part #927827-2
SPT REC 6.3 Contact SRC Sn

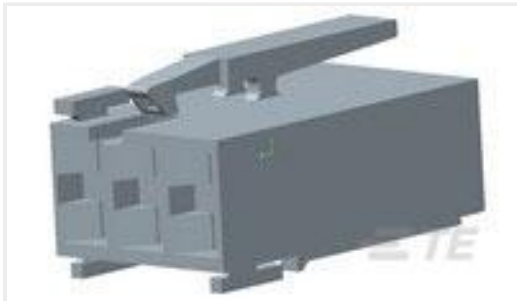


TE Part #3-1241961-7
STD TIM MK2 HSG 3P



TE Part #3-1534799-1
AMP DUOPLUG MK2 CONNECTOR 11P SELECTIVE



TE Part #4-1241961-7
STD TIM MK2 HSG 3P

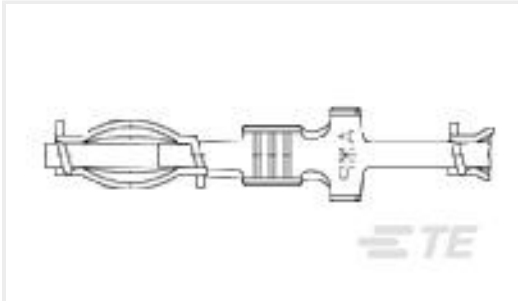

TE Part #170063-2
CLUSTER PIN REC

Documents

Product Drawings

SPT REC 6.3 Contact SRC Ag

English

CAD Files

Customer View Model

ENG_CVM_CVM_927831-4_C.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_927831-4_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_927831-4_C.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

POWER_CONNECTORS_CATALOG_SEC02_CABLE_MOUNTED

English

Product Specifications

Application Specification

German

Application Specification

English



Application Specification

English